



Installation Instruction VG-C/DC-PH1000-4

Base / Unterteil V 20-C/U-3PH-Y

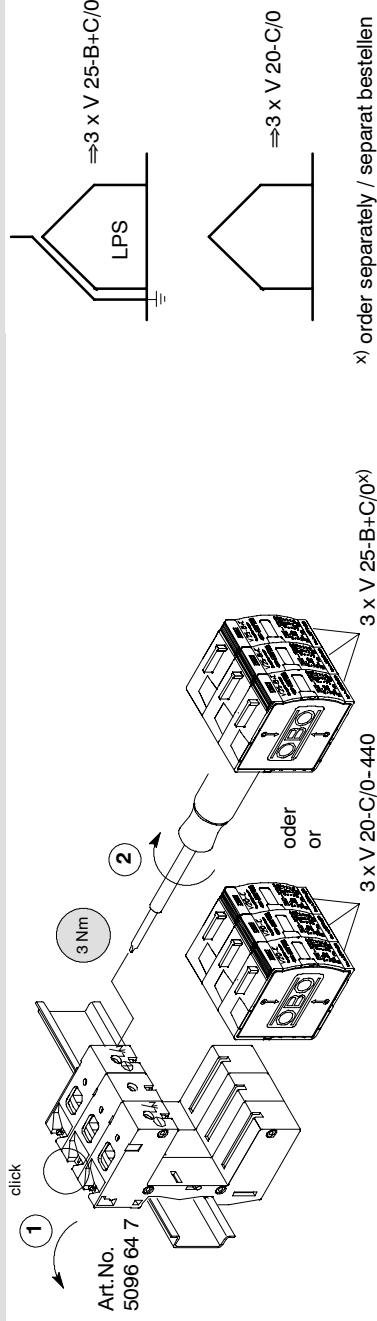


Technical Data / Technische Daten


Typ	V 20-C 0-500 PV	V 20-C 0-300 PV
U _{C DC=}	500 V	300 V
U _{C AC~}	440 V	280 V
U _{OC max}	1000 V	600 V
LPZ	LPZ 1->2	
U _p	≤ 2,0 kV	≤ 1,3 kV
U _{P(+)} (+/-)	≤ 4,0 kV	≤ 2,6 kV
I _n (8/20)	20 kA	20 kA
I _{max} (8/20)	40 kA	40 kA
I _{imp} (10/350)		
u °C		-40 °C - +80 °C
IP-Code		20
min. L, N, PE	25 mm ²	35 mm ²
max. L, N, PE		35 mm ²

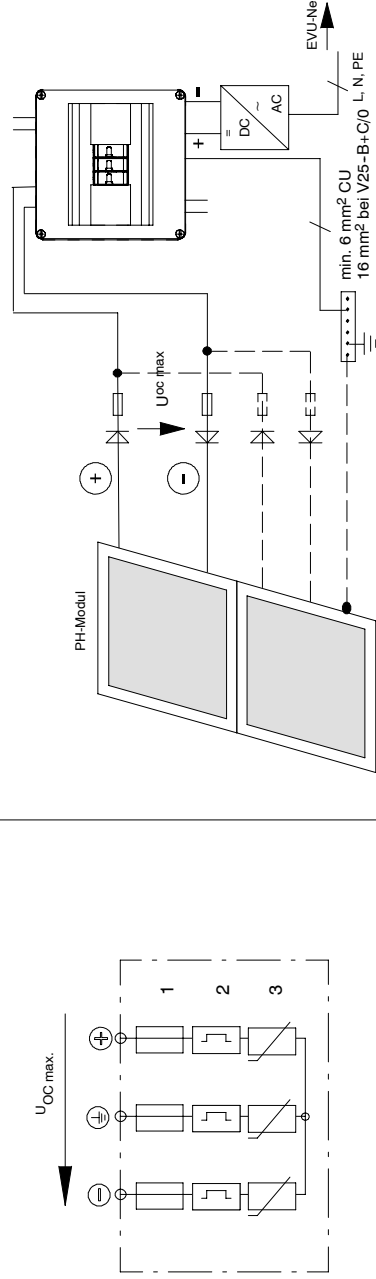


Case / Gehäuse

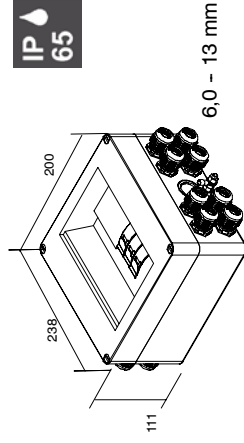


Indication / Signalisierung

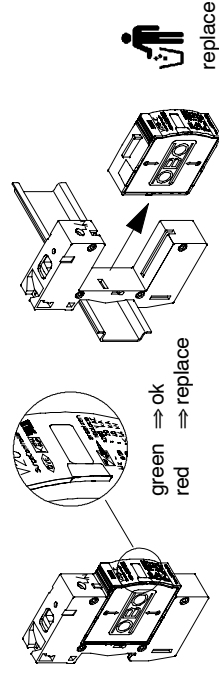

Terminals block / Anschlussklemmen

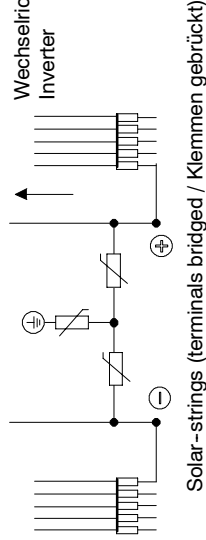

PH-Modul

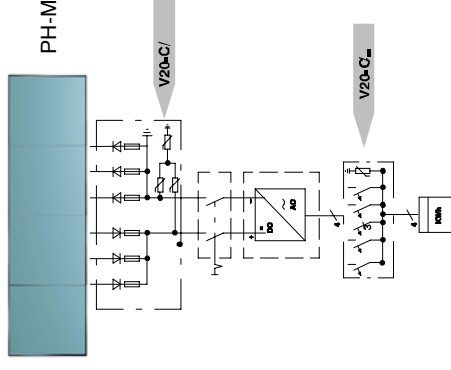

Head Office

OBO BETTERMANN GmbH & Co. KG

Postfach 1120 · 58694 Menden, Germany
 Huingser Ring 52 · D-58710 Menden
 Tel. +49 (0)2373-89-0 Fax +49 (0)2373-89-238
 E-Mail: info@obo.de · www.obo-bettermann.com

Technical Hotline

+49 (0)2373-89-1500
 +49 (0)2373-89-1550
 E-Mail: hotline@obo.de