

## Inbuilt potential equalisation

OBO LKM duct  
with new locking contour  
and optimised cover clip



Intelligent solution: the new locking contour of the enhanced OBO LKM duct ensures that potential equalisation is created between cover and lower part – entirely without accessories.

A new cover clip also simplifies overhead fitting of the cables in the ducts.



**NEW**

**OBO**  
**BETTERMANN**

# 20/40/60

Trunking depth

 


## Cable trunking, fitting


### Lid and base

Stock length: 2000 mm  
Perforated base  
Including 4 flat plugs for earthing


### Internal bend




### External bend

 

### Tee with cover

 


### Flat bend with cover

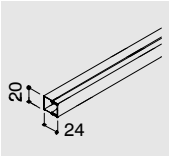


**LKM 20020**  
Packing: 20 m  
Wt: 0.482 kg/m

Surface	Ord. no.
	<b>FS</b>
galv.	<b>6246966</b>
pure white	<b>6248462</b>

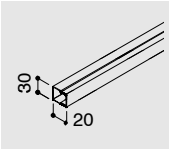

**LKM 20030**  
Packing: 20 m  
Wt: 0.332 kg/m

Surface	Ord. no.
	<b>FS</b>
galv.	<b>6246974</b>
pure white	<b>6248470</b>

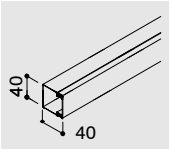

**LKM 40040**  
Packing: 16 m  
Wt: 1.218 kg/m

Surface	Ord. no.
	<b>FS</b>
galv.	<b>6246990</b>
pure white	<b>6248497</b>

**LKM/I 40040**  
Packing: 4 pcs  
Wt: 0.235 kg/pc

Ord. no.
<b>FS</b>
<b>6247652</b>
<b>6249167</b>

**LKM/A 40040**  
Packing: 4 pcs  
Wt: 0.220 kg/pc


Ord. no.
<b>FS</b>
<b>6247563</b>
<b>6249086</b>

**LKM/T 40040**  
Packing: 4 pcs  
Wt: 0.497 kg/pc

Ord. no.
<b>FS</b>
<b>6247725</b>
<b>6249256</b>

**LKM/F 40040**  
Packing: 4 pcs  
Wt: 0.349 kg/pc

Ord. no.
<b>FS</b>
<b>6247490</b>
<b>6248993</b>

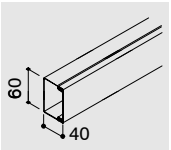

**LKM 40060**  
Packing: 8 m  
Wt: 1.410 kg/m

Surface	Ord. no.
	<b>FS</b>
galv.	<b>6247016</b>
pure white	<b>6248519</b>

**LKM/I 40060**  
Packing: 4 pcs  
Wt: 0.390 kg/pc

Ord. no.
<b>FS</b>
<b>6247660</b>
<b>6249175</b>

**LKM/A 40060**  
Packing: 4 pcs  
Wt: 0.350 kg/pc


Ord. no.
<b>FS</b>
<b>6247571</b>
<b>6249094</b>

**LKM/T 40060**  
Packing: 4 pcs  
Wt: 0.900 kg/pc

Ord. no.
<b>FS</b>
<b>6247733</b>
<b>6249264</b>

**LKM/F 40060**  
Packing: 4 pcs  
Wt: 0.480 kg/pc

Ord. no.
<b>FS</b>
<b>6247504</b>
<b>6249000</b>

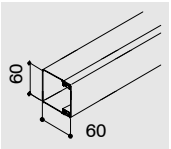

**LKM 60060**  
Packing: 8 m  
Wt: 1.840 kg/m

Surface	Ord. no.
	<b>FS</b>
galv.	<b>6247091</b>
pure white	<b>6248608</b>

**LKM/I 60060**  
Packing: 4 pcs  
Wt: 0.440 kg/pc

Ord. no.
<b>FS</b>
<b>6248128</b>
<b>6249612</b>

**LKM/A 60060**  
Packing: 4 pcs  
Wt: 0.570 kg/pc


Ord. no.
<b>FS</b>
<b>6248047</b>
<b>6249558</b>

**LKM/T 60060**  
Packing: 4 pcs  
Wt: 0.930 kg/pc

Ord. no.
<b>FS</b>
<b>6248187</b>
<b>6249671</b>

**LKM/F 60060**  
Packing: 4 pcs  
Wt: 0.750 kg/pc

Ord. no.
<b>FS</b>
<b>6247989</b>
<b>6249485</b>

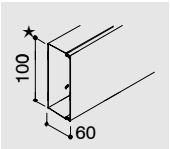

**LKM 60100**  
Packing: 8 m  
Wt: 2.100 kg/m

Surface	Ord. no.
	<b>FS</b>
galv.	<b>6247113</b>
pure white	<b>6248624</b>

**LKM/I 60100**  
Packing: 4 pcs  
Wt: 0.620 kg/pc

Ord. no.
<b>FS</b>
<b>6248144</b>
<b>6249639</b>

**LKM/A 60100**  
Packing: 4 pcs  
Wt: 0.650 kg/pc


Ord. no.
<b>FS</b>
<b>6248063</b>
<b>6249574</b>

**LKM/T 60100**  
Packing: 4 pcs  
Wt: 1.180 kg/pc

Ord. no.
<b>FS</b>
<b>6248209</b>
<b>6249701</b>

**LKM/F 60100**  
Packing: 4 pcs  
Wt: 0.900 kg/pc

Ord. no.
<b>FS</b>
<b>6248004</b>
<b>6249507</b>

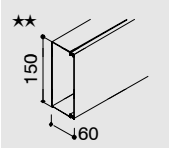

**LKM 60150**  
Packing: 8 m  
Wt: 2.650 kg/m

Surface	Ord. no.
	<b>FS</b>
galv.	<b>6247148</b>
pure white	<b>6248640</b>

**LKM/I 60150**  
Packing: 4 pcs  
Wt: 0.720 kg/pc

Ord. no.
<b>FS</b>
<b>6248152</b>
<b>6249647</b>

**LKM/A 60150**  
Packing: 4 pcs  
Wt: 0.770 kg/pc


Ord. no.
<b>FS</b>
<b>6248071</b>
<b>6249582</b>

**LKM/T 60150**  
Packing: 4 pcs  
Wt: 1.650 kg/pc

Ord. no.
<b>FS</b>
<b>6248217</b>
<b>6249728</b>

**LKM/F 60150**  
Packing: 4 pcs  
Wt: 1.330 kg/pc

Ord. no.
<b>FS</b>
<b>6248012</b>
<b>6249515</b>

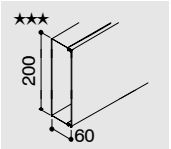

**LKM 60200**  
Packing: 8 m  
Wt: 3.210 kg/m

Surface	Ord. no.
	<b>FS</b>
galv.	<b>6247164</b>
pure white	<b>6248667</b>

**LKM/I 60200**  
Packing: 4 pcs  
Wt: 0.820 kg/pc

Ord. no.
<b>FS</b>
<b>6248160</b>
<b>6249655</b>

**LKM/A 60200**  
Packing: 4 pcs  
Wt: 0.980 kg/pc

Ord. no.
<b>FS</b>
<b>6248098</b>
<b>6249590</b>

**LKM/T 60200**  
Packing: 4 pcs  
Wt: 2.330 kg/pc


Ord. no.
<b>FS</b>
<b>6248225</b>
<b>6249736</b>

**LKM/F 60200**  
Packing: 4 pcs  
Wt: 1.960 kg/pc


Ord. no.
<b>FS</b>
<b>6248020</b>
<b>6249523</b>

**End cap**

 
Surface
galv.
pure white


**Cover**

 **LKM/D 20**  
 Packing: 10 m  
 Wt: 0.172 kg/m

Ord. no.
FS
<b>6247253</b>
<b>6248772</b>

**Partition**

**Joint connector**

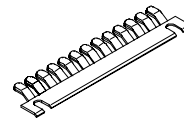**LKM/SV-20**  
 Packing: 50 pcs  
 Wt: 0.007 kg/pc

Ord. no.
G
<b>6247431</b>

**Cable holder**

**Cover clip**


Surface
galv.
pure white

**LKM/D 30**  
 Packing: 10 m  
 Wt: 0.196 kg/m

Ord. no.
FS
<b>6247256</b>
<b>6248776</b>

**LKM/SV-30**  
 Packing: 50 pc  
 Wt: 0.008 kg/pc

Ord. no.
G
<b>6247434</b>

Surface
galv.
pure white

**LKM/E 40040**  
 Packing: 10 pcs  
 Wt: 0.022 kg/pc

Ord. no.
FS
<b>6247881</b>
<b>6249418</b>

**LKM/D 40**  
 Packing: 10 m  
 Wt: 0.394 kg/m

Ord. no.
FS
<b>6247261</b>
<b>6248780</b>

**LKM/SV-40**  
 Packing: 50 pcs  
 Wt: 0.010 kg/pc

Ord. no.
VA
<b>6247458</b>

Surface
galv.
pure white

**LKM/E 40060**  
 Packing: 10 pcs  
 Wt: 0.028 kg/pc

Ord. no.
FS
<b>6247903</b>
<b>6249426</b>

**LKM/D 60**  
 Packing: 8 m  
 Wt: 0.512 kg/m

Ord. no.
FS
<b>6247318</b>
<b>6248802</b>

**LKM/SV-40**  
 Packing: 50 pcs  
 Wt: 0.010 kg/pc

Ord. no.
VA
<b>6247458</b>

**LKM/Z 60**  
 Packing: 10 pcs  
 Wt: 0.009 kg/pc

Ord. no.
FS
<b>6249906</b>

Surface
galv.
pure white

**LKM/E 60060**  
 Packing: 4 pcs  
 Wt: 0.020 kg/pc

Ord. no.
FS
<b>6248284</b>
<b>6249795</b>

**LKM/D 60**  
 Packing: 8 m  
 Wt: 0.512 kg/m

Ord. no.
FS
<b>6247318</b>
<b>6248802</b>

**LKM/SV-60**  
 Packing: 50 pcs  
 Wt: 0.016 kg/pc

Ord. no.
FS
<b>6247466</b>

**LKM/Z 60**  
 Packing: 10 pcs  
 Wt: 0.009 kg/pc

Ord. no.
FS
<b>6249906</b>

Surface
galv.
pure white

**LKM/E 60100**  
 Packing: 10 pcs  
 Wt: 0.062 kg/pc

Ord. no.
FS
<b>6248306</b>
<b>6249817</b>

**LKM/D 100**  
 Packing: 8 m  
 Wt: 0.774 kg/m

Ord. no.
FS
<b>6247342</b>
<b>6248837</b>

**LKM/TWS55**  
 Packing: 32 m  
 Wt: 0.698 kg/m

Ord. no.
FS
<b>6249876</b>

**LKM/SV-60**  
 Packing: 50 pcs  
 Wt: 0.016 kg/pc

Ord. no.
FS
<b>6247466</b>

**LKM/Z 100**  
 Packing: 10 pcs  
 Wt: 0.015 kg/pc

Ord. no.
FS
<b>6249922</b>

**LKM/K-80**  
 Packing: 20 pcs  
 Wt: 0.026 kg/pc

Ord. no.
<b>6249884</b>

Surface
galv.
pure white

**LKM/E 60150**  
 Packing: 10 pcs  
 Wt: 0.085 kg/pc

Ord. no.
FS
<b>6248314</b>
<b>6249825</b>

**LKM/D 150**  
 Packing: 8 m  
 Wt: 1.040 kg/m

Ord. no.
FS
<b>6247377</b>
<b>6248861</b>

**LKM/TWS55**  
 Packing: 32 m  
 Wt: 0.698 kg/m

Ord. no.
FS
<b>6249876</b>

**LKM/SV-60**  
 Packing: 50 pcs  
 Wt: 0.016 kg/pc

Ord. no.
FS
<b>6247466</b>

**LKM/Z 150**  
 Packing: 10 pcs  
 Wt: 0.030 kg/pc

Ord. no.
FS
<b>6249965</b>

**LKM/K-140**  
 Packing: 20 pcs  
 Wt: 0.035 kg/pc

Ord. no.
<b>6249888</b>

Surface
galv.
pure white

**LKM/E 60200**  
 Packing: 10 pcs  
 Wt: 0.109 kg/pc

Ord. no.
FS
<b>6248322</b>
<b>6249833</b>

**LKM/D 200**  
 Packing: 8 m  
 Wt: 1.336 kg/m

Ord. no.
FS
<b>6247393</b>
<b>6248896</b>

**LKM/TWS55**  
 Packing: 32 m  
 Wt: 0.698 kg/m

Ord. no.
FS
<b>6249876</b>

**LKM/SV-60**  
 Packing: 50 pcs  
 Wt: 0.016 kg/pc

Ord. no.
FS
<b>6247466</b>

**LKM/Z 200**  
 Packing: 10 pcs  
 Wt: 0.044 kg/pc

Ord. no.
FS
<b>6249981</b>

**LKM/K-140**  
 Packing: 20 pcs  
 Wt: 0.035 kg/pc

Ord. no.
<b>6249888</b>

# OBO's networked systems.

<p><b>VBS</b> Connection and fastening systems</p>		<p>Connection systems Fastening systems Beam clamp systems Rail systems Screw-in and knock-in systems</p>
<p><b>TBS</b> Transient voltage and lightning protection systems</p>		<p>Surge protection systems Equipotential bonding systems Earthing systems Lightning protection systems</p>
<p><b>KTS</b> Cable support systems</p>		<p>Mounting systems Cable tray systems Mesh cable tray systems Cable ladder systems Vertical ladder systems Modular systems Luminaire support systems Distribution boxes Rangierverteiler-Systeme Stainless-steel components</p>
<p><b>BSS</b> Fire protection systems</p>		<p>Cable insulation Function maintenance Fire protection ducts</p>
<p><b>LFS</b> Cable routing systems</p>		<p>Installation duct systems Skirting duct systems IBIS Integral Media columns</p>
<p><b>UFS</b> Underfloor systems</p>		<p>Underfloor installation systems ISO A duct system Cavity and false floor systems</p>