 

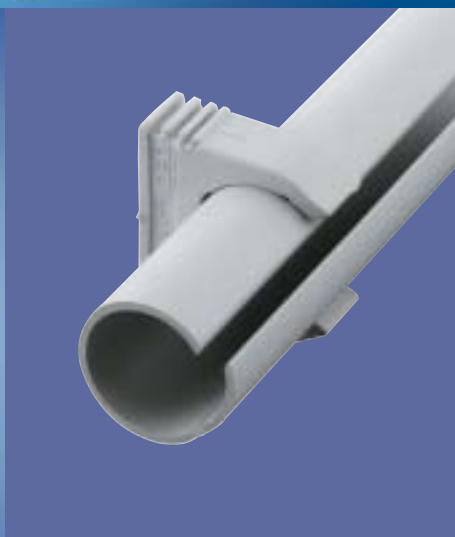



# "Close, Sesame"

## OBO Quick-Pipe

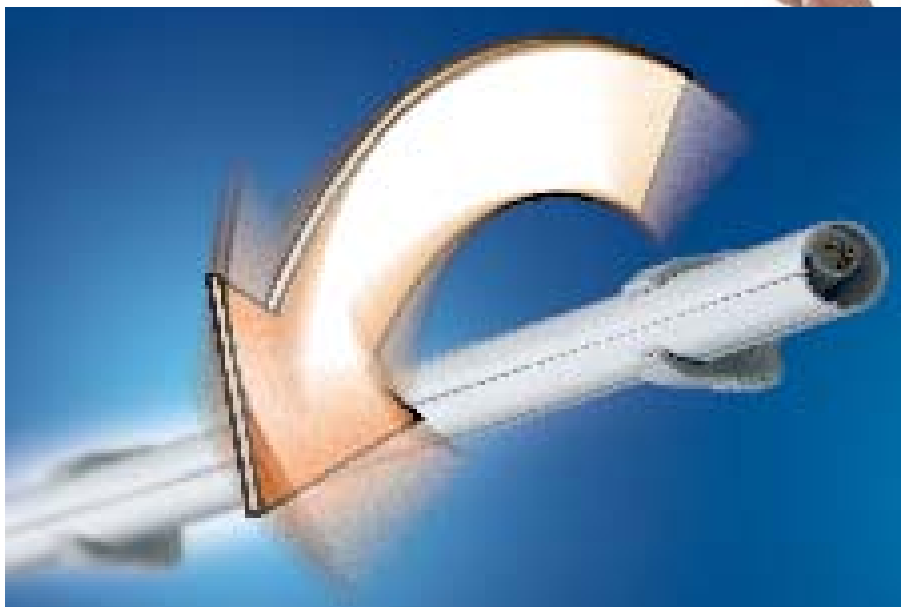


# OBO Quick-Pipe

The clever pipe system  
with a twist

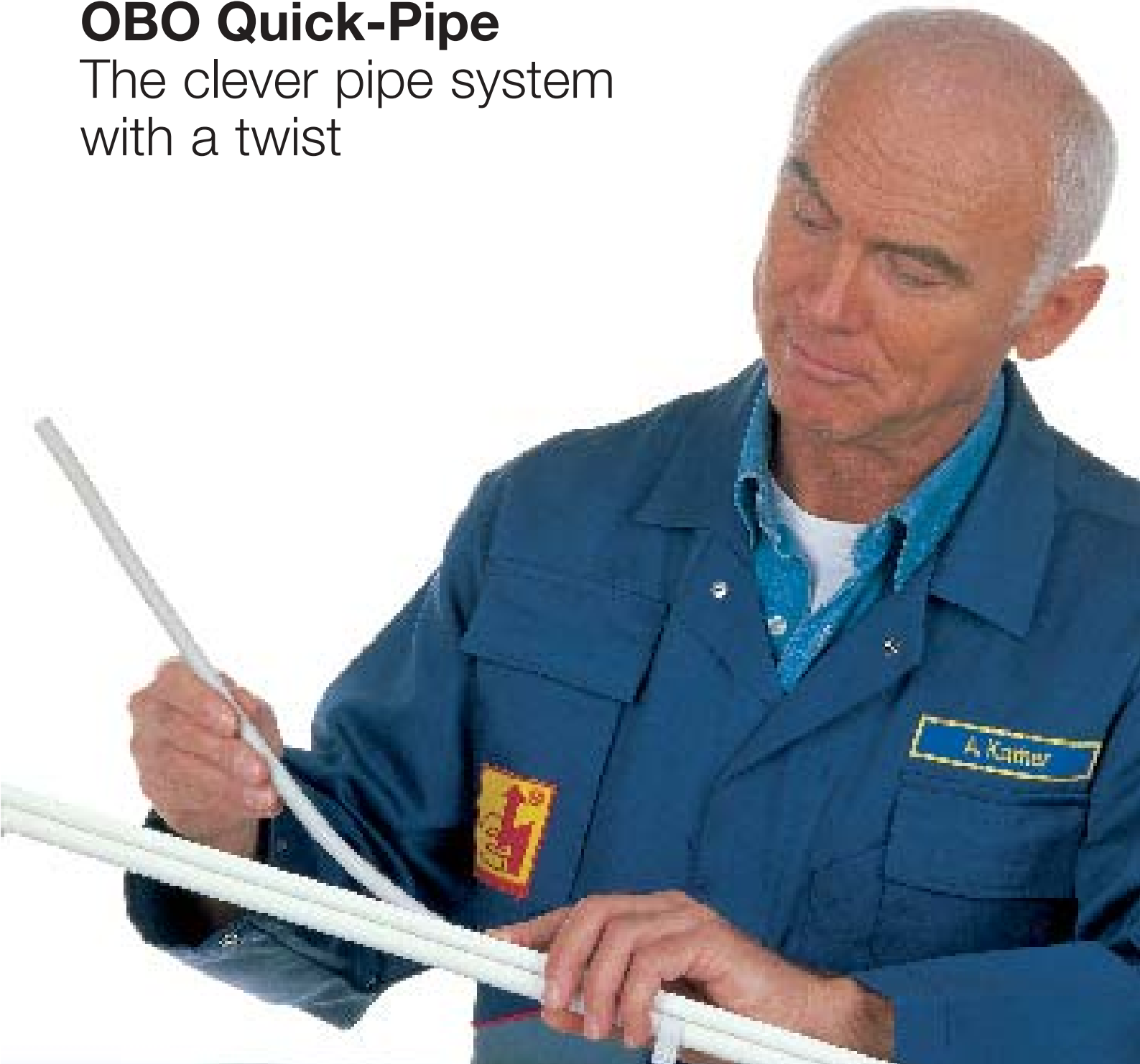

## Parts

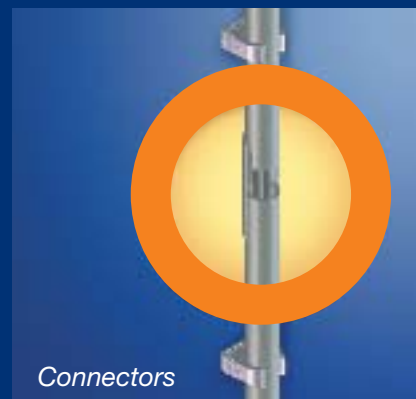



### The clever combination

The new closable OBO Quick-Pipe is the clever combination of conventional pipe and open cable installation.

Ideal for walls and ceilings, and the perfect choice for a tidy and secure surface mounted installation where the cables need protection from damage, dust and dirt.

### Insert cable - turn - finished

Quick-Pipes have a cover which automatically closes when the pipe is turned. Quick-Pipe can be used with the Junior Quick Clips which have already been used successfully millions of times. Installation using the OBO Quick-Pipe is simple:

- Clip Quick-Pipe into the Junior Quick-Clip.
- Install cable into the Quick-Pipe through slot.
- Twist the OBO Quick-Pipe towards the back.
- Finished.

The clever design automatically closes the cover on the Quick-Pipe.

### A complete system

Special fittings match the Quick-Pipe in design and function, ensures easy connection. Connectors, bends and T-pieces are a two-part construction and can easily be fitted later. The pipe can also be adjusted sideways. The 90° bend can be used for both internal and external corners.

The fittings can be opened again easily after installation, for example later additions of cables, or changes in design.

### Other system benefits


The patented Quick-Pipe system not only offers a neat appearance for surface-mounted installations and safe protection of the cables against dirt and contact, but also has a number of other benefits:

For example, Quick-Pipe is ideal for the installation of fibre optic cables, in conjunction with the fittings the cables can be inserted into the pipe through the slot, minimising the risk of kinking or damage.

Pre-assembled cables with plugs or connectors fitted can easily be installed through the slots in the pipe.

### Dimensions


The OBO Quick-Pipe is available in metric dimensions M16, M20, M25 and M32 at standard lengths of 2 metres.

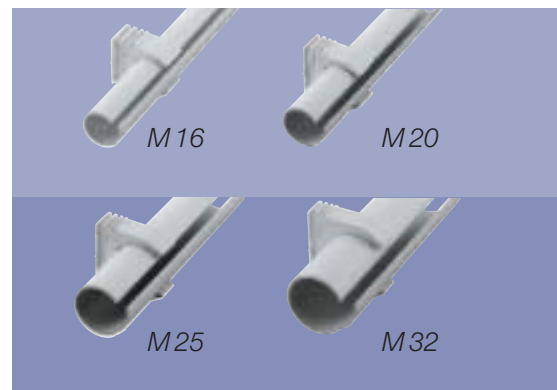

### Installing the fittings




## Order data

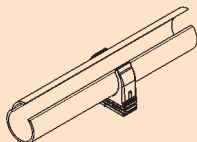

### Set of OBO Quick-Pipe and OBO Junior-Quick clips

 Type	Colour	Outer carton	Supply length m	Weight kg/% m	Order No. PVC
<b>2954/M 16</b>	light grey	50m Quick-Pipe 156 Junior Quick	2	4,440	<b>2154 50 1</b>
<b>2954/M 20</b>	light grey	40m Quick-Pipe 120 Junior Quick	2	5,080	<b>2154 52 8</b>
<b>2954/M 25</b>	light grey	30m Quick-Pipe 96 Junior Quick	2	5,170	<b>2154 53 6</b>
<b>2954/M 32</b>	light grey	20m Quick-Pipe 60 Junior Quick	2	4,790	<b>2154 54 4</b>



### OBO Junior-Quick clip

Type	Nominal size metric pipe	Colour	Outer carton/ pieces	Packing pc	Weight kg/% pc	Order No. PP
<b>2950/M 16</b>	M 16	light grey	1300	100	0,260	<b>2154 10 2</b>
<b>2950/M 20</b>	M 20	light grey	1200	100	0,330	<b>2154 12 9</b>
<b>2950/M 25</b>	M 25	light grey	1200	100	0,430	<b>2154 27 7</b>
<b>2950/M 32</b>	M 32	light grey	600	50	0,580	<b>2154 28 5</b>

Please refer to our VBS main catalogue for our entire program of connecting and fastening systems!

**VBS**  
Connecting and fastening systems

Connecting systems  
Fastening systems  
Support clamp systems  
Rail systems  
Screw and hammer systems

Earthing systems  
Equipotential bonding systems  
Lightning protection systems  
Overvoltage protection systems