

## Staying flexible

The new WDK ducts with practical cover clip



The new cover clip greatly facilitates the fitting of OBO's WDK ducts. The clip is continuously adjustable over the whole length of the duct. This means you can stay flexible and mobile during installation.

Another plus is the simplicity of cable insertion: the clip is locked in on one side and tilted forward. This gives a 30° opening, so that the cables can be laid in quickly and without problems.


From a duct width of 100 mm the clip can also be used as a connector in the fitting of line routing ducts. When supplied the cover clip is attached to the bottom of the duct.



**OBO**  
BETTERMANN


The new cover clip is continuously adjustable.

When inserting the cables the clip is locked in on one side and tilted forward. A 30° opening angle facilitates the loading of the ducts.

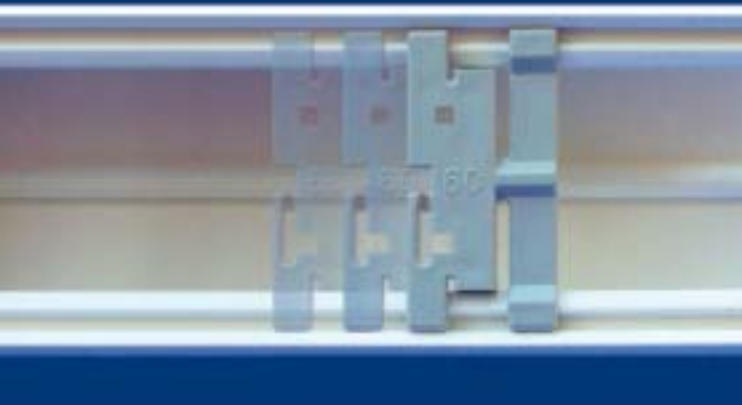


### Lid and base

Stock length: 2000 mm  
Perforated base  
from WDK 40060: 4 cover clips included

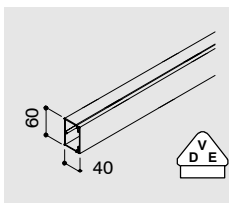

**WDK 40060**  
Pack qty: 24 m  
Wt: 0.480 kg/m

Colour	Order no. PVC
grey	6025633
white	6020887
light grey	6027024
pure white	6191134

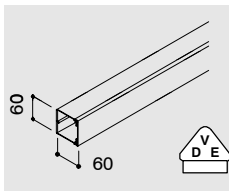

**WDK 60060**  
Pack qty: 32 m  
Wt: 0.600 kg/m

Colour	Order no. PVC
grey	6025668
white	6021948
light grey	6027105
pure white	6191193

### Internal bend



**WDK/HI 40060**  
Pack qty: 2 pc  
Wt: 0.080 kg/pc

Order no. PVC
6021719
6160107
6182127
6191959

 
### External bend



**WDK/HA 40060**  
Pack qty: 2 pc  
Wt: 0.095 kg/pc

Order no. PVC
6021697
6160700
6182534
6192254


### Tee and intersection closer



**WDK/HK 40060**  
Pack qty: 2 pc  
Wt: 0.130 kg/pc

Order no. PVC
6023312
6162002
6182925
6192556

### Flat bend

 

**WDK/HF 40060**  
Pack qty: 2 pc  
Wt: 0.065 kg/pc

Colour	Order no. PVC
grey	6021735
white	6161308
light grey	6183344
pure white	6192858


### End cap



 **WDK/HE 40060**  
Pack qty: 20 pc  
Wt: 0.012 kg/pc

Order no. PVC
6021492
6162606
6183735
6193226


### Cover



**2410/60**  
Pack qty: 44 m  
Wt: 0.125 kg/m

Order no. PVC
6022685
6027660
6028136
6191592


### Partition

 

**2371/4/6**  
Pack qty: 60 m  
Wt: 0.135 kg/m

Order no. PVC
6023282

### Cover clip

 

**2370/60**  
Pack qty: 100 pc  
Wt: 0.600 kg/pc

Order no. PVC
6022995

### WDK/HF 60060

Pack qty: 2 pc  
Wt: 0.084 kg/pc

Colour	Order no. PVC
grey	6022448
white	6161502
light grey	6183409
pure white	6192912

### WDK/HE 60060

Pack qty: 20 pc  
Wt: 0.015 kg/pc

Order no. PVC
6022499
6162800
6183808
6193285

### 2410/60

Pack qty: 44 m  
Wt: 0.125 kg/m

Order no. PVC
6022685
6027660
6028136
6191592

### TW 8

Pack qty: 40 m  
Wt: 0.220 kg/m

Order no. PVC
6270638

### 2370/60

Pack qty: 100 pc  
Wt: 0.600 kg/pc

Order no. PVC
6022995

## OBO BETTERMANN GmbH & Co.

P. O. Box 1120 · 58694 Menden · Germany  
Tel. +49 (0)23 73 89-0 · Fax +49 (0)23 73 89-238  
E-mail: info@obo.de · www.obo-bettermann.com

## Central technical hotline

Tel. +49 (0)23 73 89-15 00  
Fax +49 (0)23 73 89-15 50  
E-mail hotline@obo.de

**OBO**  
**BETTERMANN**