

Technical data sheet

Tensioning wire clip A4

Item number: 1404292



Tensioning wire clip for cable 4–9 mm 19–28 mm. With V4A bolt M4x14.



A4	Stainless steel
2B	Bright, treated

Master data

Item number	1404292
Type	1020 18-28 A4
Description 1	Tensioning wire clip
Description 2	for cable 4-9 mm
Manufacturer	OBO
Dimension	19-28mm
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1254 kg COe / 1 Piece


Technical data sheet

Tensioning wire clip A4

Item number: 1404292



Dimensions

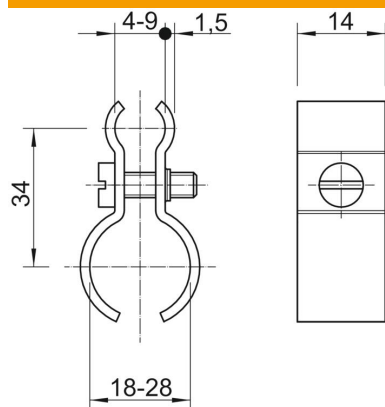

Dimension A	34 mm
-------------	-------

Technical data

Number of cables/pipes	1
Version for	Not insulated
Bolt	M4x14