

Technical data sheet

Flat cable threaded connection, PG thread rectangular version, stone grey

Item number: 2012928



Flat-cable entry, choke-nipple design with PG connecting thread to DIN 40430, protection rating IP31, with pre-mounted support sealing ring 107/F.



PE Polyethylene

Master data

Item number	2012928
Type	106 FL 21 14 40
Description 1	Flat cable threaded connection
Manufacturer	OBO
Dimension	PG21
Colour	Stone grey; RAL 7030
Material	Polyethylene
Smallest sales unit	25
Unit of quantity	Piece
Weight	2.015 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0833 kg COe / 1 Piece


Technical data sheet

Flat cable threaded connection, PG thread rectangular version, stone grey

Item number: 2012928



Dimensions

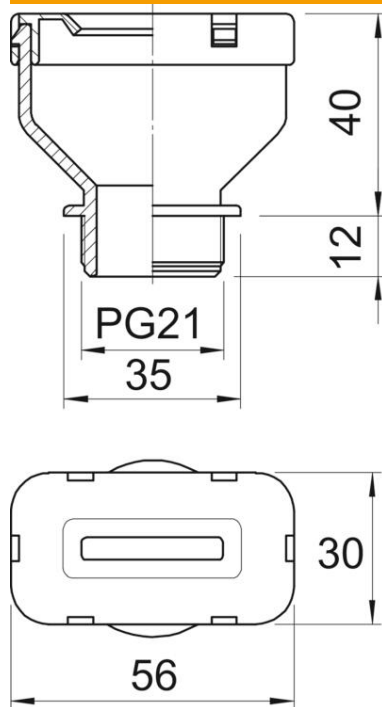

Dimension A	30 mm
Dimension B	56 mm
Dimension D	35 mm
Dimension G	PG21 mm
Dimension L	52 mm
Dimension L1	12 mm
Dimension L2	40 mm

Technical data

Type of seal	Sealing ring
Version for	Straight
Bend protection	no
Flat cable/width, max.	40 mm
Flat cable/width, min.	37 mm
Flat cables/thickness, max.	14 mm
Flat cables/thickness, min.	11 mm
Flat cable gland	yes
For Ex zone	Without
Thread	Pg 21
Thread type	PG
Fibre-glass reinforced	no
Sealing insert, multiple	no
With locknut	no
Impact-resistant	no
Protection rating	IP31
Strain relief option	no