

Technical data sheet

Flat cable threaded connection, metric thread M20, stone grey

Item number: 2013002



Flat-cable entry, choke-nipple design with metric connecting thread to IEC 432, protection rating IP31, with pre-mounted support sealing ring 107/F.



Master data

Item number	2013002
Type	106 FL M20 8 19
Description 1	Flat cable threaded connection
Manufacturer	OBO
Dimension	M20
Colour	Stone grey; RAL 7030
Material	Polyethylene
Smallest sales unit	50
Unit of quantity	Piece
Weight	0.909 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0607 kg COe / 1 Piece


Technical data sheet

Flat cable threaded connection, metric thread M20, stone grey

Item number: 2013002



Dimensions

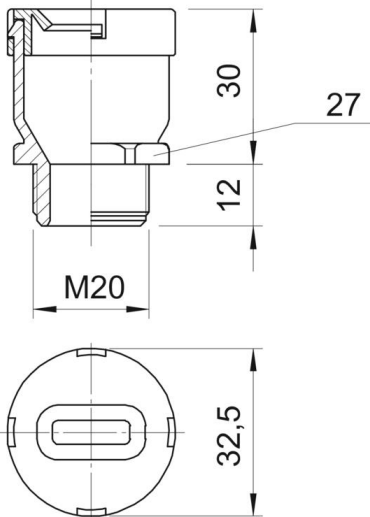

Dimension D	32.5 mm
Dimension G	M20 mm
Dimension L	42 mm
Dimension L1	12 mm
Dimension L2	30 mm

Technical data

Type of seal	Sealing ring
Version for	Straight
Bend protection	no
explosion-proof	no
Flat cable/width, max.	19 mm
Flat cable/width, min.	17 mm
Flat cables/thickness, max.	8 mm
Flat cables/thickness, min.	6 mm
Flat cable gland	yes
For Ex zone	Without
Thread	M20
Thread type	Metric
Fibre-glass reinforced	no
Sealing insert, multiple	no
With locknut	no
Impact-resistant	no
WAF	27
Protection rating	IP31
Strain relief option	no