

Technical data sheet

Flat cable threaded connection, metric thread M32, stone grey

Item number: 2013020



Flat-cable entry, choke-nipple design with metric connecting thread to IEC 432, protection rating IP31, with pre-mounted support sealing ring 107/F.



PE Polyethylene

Master data

Item number	2013020
Type	106 FL M32 10 31
Description 1	Flat cable threaded connection
Manufacturer	OBO
Dimension	M32
Colour	Stone grey; RAL 7030
Material	Polyethylene
Smallest sales unit	15
Unit of quantity	Piece
Weight	3.45 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1081 kg COe / 1 Piece


Technical data sheet

Flat cable threaded connection, metric thread M32, stone grey

Item number: 2013020



Dimensions

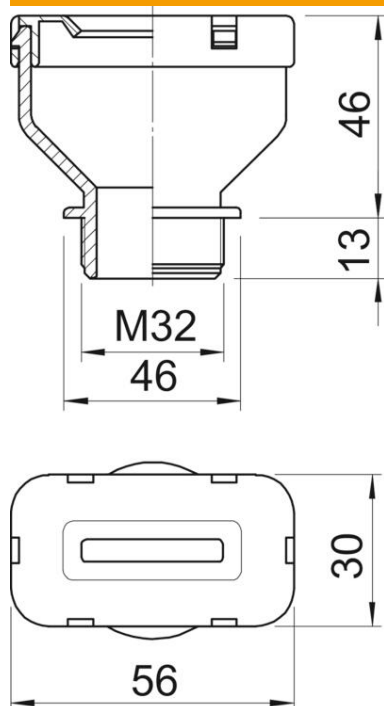

Dimension A	30 mm
Dimension B	56 mm
Dimension D	46 mm
Dimension G	M32 mm
Dimension L	59 mm
Dimension L1	13 mm
Dimension L2	46 mm

Technical data

Type of seal	Sealing ring
Version for	Straight
Bend protection	yes
explosion-proof	no
Flat cable/width, max.	31.5 mm
Flat cable/width, min.	28.5 mm
Flat cables/thickness, max.	10.5 mm
Flat cables/thickness, min.	8.5 mm
Flat cable gland	yes
For Ex zone	Without
Thread	M32
Thread type	Metric
Fibre-glass reinforced	no
Sealing insert, multiple	no
With locknut	no
Impact-resistant	no
Protection rating	IP31
Strain relief option	no