

# Technical data sheet

Flat cable threaded connection, metric thread M32, stone grey

Item number: 2013021



Flat-cable entry, choke-nipple design with metric connecting thread to IEC 432, protection rating IP31, with pre-mounted support sealing ring 107/F.



**PE** Polyethylene

## Master data

|                                   |                                |
|-----------------------------------|--------------------------------|
| Item number                       | 2013021                        |
| Type                              | 106 FL M32 12 35               |
| Description 1                     | Flat cable threaded connection |
| Manufacturer                      | OBO                            |
| Dimension                         | M32                            |
| Colour                            | Stone grey; RAL 7030           |
| Material                          | Polyethylene                   |
| Smallest sales unit               | 15                             |
| Unit of quantity                  | Piece                          |
| Weight                            | 3.45 kg                        |
| Weight unit                       | kg/100 pc.                     |
| CO Footprint (GWP) Cradle-to-Gate | 0,1077 kg COe / 1 Piece        |


# Technical data sheet

Flat cable threaded connection, metric thread M32, stone grey

Item number: 2013021



## Dimensions

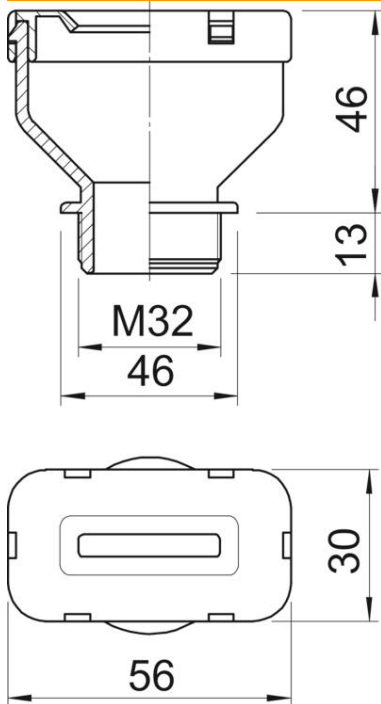

|              |        |
|--------------|--------|
| Dimension A  | 30 mm  |
| Dimension B  | 56 mm  |
| Dimension D  | 46 mm  |
| Dimension G  | M32 mm |
| Dimension L  | 59 mm  |
| Dimension L1 | 13 mm  |
| Dimension L2 | 46 mm  |

## Technical data

|                             |              |
|-----------------------------|--------------|
| Type of seal                | Sealing ring |
| Version for                 | Straight     |
| Bend protection             | yes          |
| explosion-proof             | no           |
| Flat cable/width, max.      | 35 mm        |
| Flat cable/width, min.      | 31 mm        |
| Flat cables/thickness, max. | 12 mm        |
| Flat cables/thickness, min. | 9 mm         |
| Flat cable gland            | yes          |
| For Ex zone                 | Without      |
| Thread                      | M32          |
| Thread type                 | Metric       |
| Fibre-glass reinforced      | no           |
| Sealing insert, multiple    | no           |
| With locknut                | no           |
| Impact-resistant            | no           |
| Protection rating           | IP31         |
| Strain relief option        | no           |