

Technical data sheet

Cone cable gland, PG thread, light grey

Item number: 2036215



Standard cable gland, shape A, to DIN 46320 with simple NR/SBR sealing ring.  
PG connection thread in accordance with DIN 40430.  
Protection rating: with connection thread sealing ring IP65, without connection thread sealing ring IP54.  
Note: Only tighten polystyrene cable glands lightly due to the risk of stress crack formation.  
Shock-resistant



| Master data |                                   |                         |
|-------------|-----------------------------------|-------------------------|
|             | Item number                       | 2036215                 |
|             | Type                              | 106 PG21                |
|             | Description 1                     | Cable gland             |
|             | Manufacturer                      | OBO                     |
|             | Dimension                         | PG21                    |
|             | Colour                            | Light grey; RAL 7035    |
|             | Material                          | Polystyrene             |
|             | Smallest sales unit               | 50                      |
|             | Unit of quantity                  | Piece                   |
|             | Weight                            | 1.76 kg                 |
|             | Weight unit                       | kg/100 pc.              |
|             | CO Footprint (GWP) Cradle-to-Gate | 0,0773 kg COe / 1 Piece |


# Technical data sheet

## Cone cable gland, PG thread, light grey

Item number: 2036215



### Dimensions

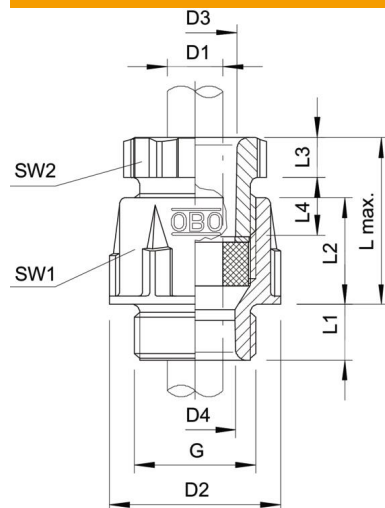

|                  |         |
|------------------|---------|
| Length           | 37.5 mm |
| Width            | 37.5 mm |
| Height           | 48 mm   |
| Dimension D1     | 18 mm   |
| Dimension D2     | 37.5 mm |
| Dimension D3     | 21.2 mm |
| Dimension D4     | 21 mm   |
| Dimension G      | Pg21 mm |
| Dimension L max. | 38 mm   |
| Dimension L1     | 10 mm   |
| Dimension L2     | 19 mm   |
| Dimension L3     | 7 mm    |
| Dimension L4     | 17 mm   |

### Technical data

|                          |              |
|--------------------------|--------------|
| Type of seal             | Sealing ring |
| Version for              | Straight     |
| Bend protection          | no           |
| Sealing area D, max.     | 18 mm        |
| Sealing area D, min.     | 14 mm        |
| explosion-proof          | no           |
| For Ex zone              | Without      |
| For Ex zone gas          | Without      |
| For Ex zone dust         | Without      |
| Thread                   | Pg 21        |
| Thread type              | PG           |
| Thread length            | 11 mm        |
| Nominal thread size      | 21           |
| Fibre-glass reinforced   | no           |
| Halogen-free             | yes          |
| Sealing insert, multiple | no           |
| With locknut             | no           |
| Impact-resistant         | no           |
| WAF 1                    | 33 mm        |
| WAF 2                    | 30 mm        |
| Protection rating        | IP65         |
| Splittable gland         | no           |
| Strain relief option     | no           |