

Technical data sheet

Screw plug, metric and PG

Item number: 2029517



Screw plug in Light grey; RAL 7035 for dust-proof and waterproof closure of installed but (as yet) unfilled V-TEC... cable glands.



PA Polyamide

Master data

Item number	2029517
Type	107VS VM 12 PA
Description 1	Screw plug
Manufacturer	OBO
Dimension	12mm
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	50
Unit of quantity	Piece
Weight	0.13 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0016 kg COe / 1 Piece


Technical data sheet

Screw plug, metric and PG

Item number: 2029517



Dimensions

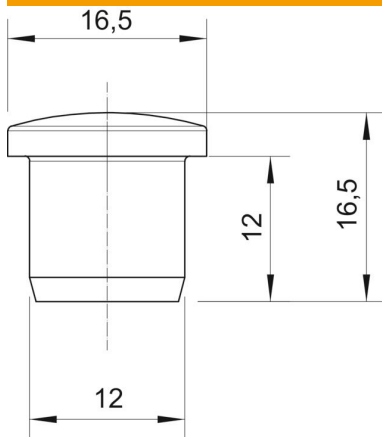

Dimension D1	12 mm
Dimension D2	16.5 mm
Dimension H	16.5 mm
Dimension L	12 mm

Technical data

Version for	Miscellaneous
explosion-proof	no
For Ex zone gas	Without
For Ex zone dust	Without
Suitable for metric thread dimension	20
Screw for PG thread dimension	16
Thread type	Metric
Nominal thread size metric/PG	20
Fibre-glass reinforced	yes
Size	M20 / Pg16
Halogen-free	yes
Inner diameter	12 mm
Impact-resistant	no
Permitted temperature range, max.	100 °C
Permitted temperature range, min.	-40 °C