

Technical data sheet

Screw plug, metric and PG

Item number: 2029520



Screw plug in Light grey; RAL 7035 for dust-proof and waterproof closure of installed but (as yet) unfilled V-TEC... cable glands.

PA Polyamide

Master data

Item number	2029520
Type	107VS VM 16 PA
Description 1	Screw plug
Manufacturer	OBO
Dimension	16mm
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	50
Unit of quantity	Piece
Weight	0.19 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0022 kg COe / 1 Piece


Technical data sheet

Screw plug, metric and PG

Item number: 2029520



Dimensions

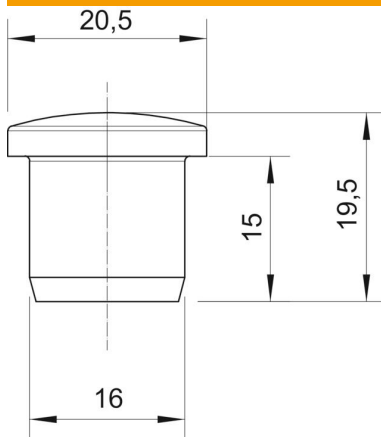

Dimension D1	16 mm
Dimension D2	20.5 mm
Dimension H	19.5 mm
Dimension L	15 mm

Technical data

Version for	Miscellaneous
explosion-proof	no
For Ex zone gas	Without
For Ex zone dust	Without
Suitable for metric thread dimension	25
Screw for PG thread dimension	21
Thread type	Metric
Nominal thread size metric/PG	25
Fibre-glass reinforced	yes
Size	M25 / Pg21
Halogen-free	yes
Inner diameter	16 mm
Impact-resistant	no
Permitted temperature range, max.	100 °C
Permitted temperature range, min.	-40 °C