

Technical data sheet

Screw plug, metric and PG

Item number: 2029533



Screw plug in Light grey; RAL 7035 for dust-proof and waterproof closure of installed but (as yet) unfilled V-TEC... cable glands.

PA Polyamide

Master data

Item number	2029533
Type	107VS VM 35 PA
Description 1	Screw plug
Manufacturer	OBO
Dimension	35mm
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	5
Unit of quantity	Piece
Weight	0.5 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0221 kg COe / 1 Piece


Technical data sheet

Screw plug, metric and PG

Item number: 2029533



Dimensions

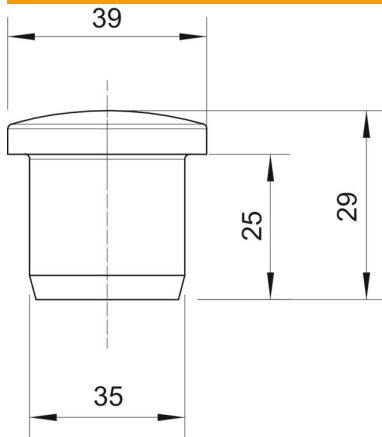

Dimension D1	35 mm
Dimension D2	39 mm
Dimension H	29 mm
Dimension L	25 mm

Technical data

Version for	Miscellaneous
explosion-proof	no
For Ex zone gas	Without
For Ex zone dust	Without
Suitable for metric thread dimension	50
Screw for PG thread dimension	42
Thread type	Metric
Nominal thread size metric/PG	50
Fibre-glass reinforced	yes
Size	M50 / Pg42
Halogen-free	yes
Inner diameter	35 mm
Impact-resistant	no
Permitted temperature range, max.	100 °C
Permitted temperature range, min.	-40 °C