

# Technical data sheet

## Screw plug, metric and PG

Item number: 2029514



Screw plug in Light grey; RAL 7035 for dust-proof and waterproof closure of installed but (as yet) unfilled V-TEC... cable glands.

**PA** Polyamide

### Master data

|                                   |                         |
|-----------------------------------|-------------------------|
| Item number                       | 2029514                 |
| Type                              | 107VS VM 9 PA           |
| Description 1                     | Screw plug              |
| Manufacturer                      | OBO                     |
| Dimension                         | 9,5mm                   |
| Colour                            | Light grey; RAL 7035    |
| Material                          | Polyamide               |
| Smallest sales unit               | 50                      |
| Unit of quantity                  | Piece                   |
| Weight                            | 0.09 kg                 |
| Weight unit                       | kg/100 pc.              |
| CO Footprint (GWP) Cradle-to-Gate | 0,0012 kg COe / 1 Piece |


# Technical data sheet

## Screw plug, metric and PG

Item number: 2029514



### Dimensions

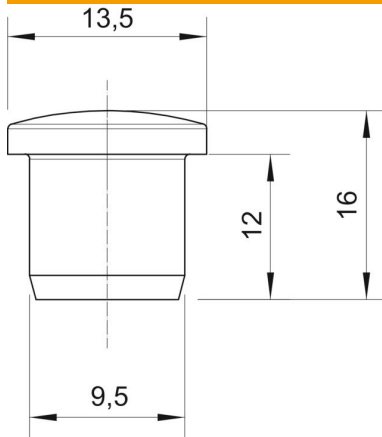

|              |         |
|--------------|---------|
| Dimension D1 | 9.5 mm  |
| Dimension D2 | 13.5 mm |
| Dimension H  | 16 mm   |
| Dimension L  | 12 mm   |

### Technical data

|                                      |               |
|--------------------------------------|---------------|
| Version for                          | Miscellaneous |
| explosion-proof                      | no            |
| For Ex zone gas                      | Without       |
| For Ex zone dust                     | Without       |
| Suitable for metric thread dimension | 16            |
| Screw for PG thread dimension        | 13.5          |
| Thread type                          | Metric        |
| Nominal thread size metric/PG        | 16            |
| Fibre-glass reinforced               | yes           |
| Size                                 | M16 / Pg13,5  |
| Halogen-free                         | yes           |
| Inner diameter                       | 9.5 mm        |
| Impact-resistant                     | no            |
| Permitted temperature range, max.    | 100 °C        |
| Permitted temperature range, min.    | -40 °C        |