


Technical data sheet

Cutting ring

Item number: 2029138

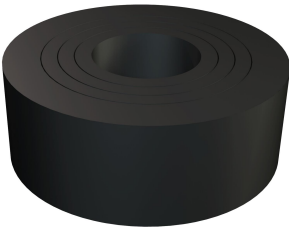

Rubber cutting ring (cuttable sealing ring) to DIN 46320 for cone cable gland.

Pg

NBR
SBR

Rubber mixture

Master data		
Item number	2029138	
Type	107 B PG13.5	
Description 1	Cutting ring	
Manufacturer	OBO	
Dimension	PG13,5	
Colour	Black	
Material	Rubber mixture	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	0.172 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,0073 kg COe / 1 Piece	


Technical data sheet

Cutting ring

Item number: 2029138



Dimensions

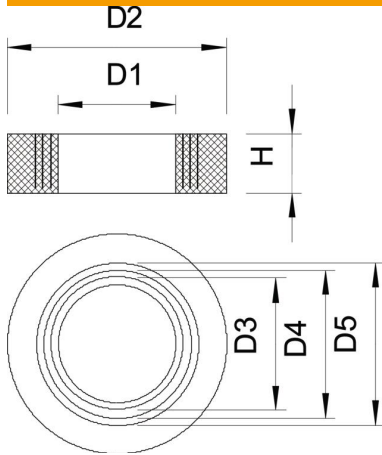

Dimension D1	7.5 mm
Dimension D2	18.3 mm
Dimension D3	10 mm
Dimension D4	12.5 mm
Dimension D5	15 mm
Dimension H	6 mm

Technical data

Sealing area D, max.	12.5 mm
Sealing area D, min.	7.5 mm
Size	Pg 13,5
Size	M20