


Technical data sheet

Cutting ring

Item number: 2029367

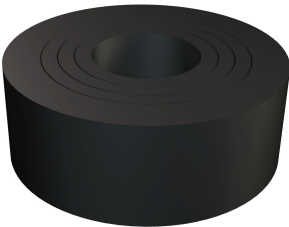

Rubber cutting ring (cuttable sealing ring) to DIN 46320 for cone cable gland.

Pg

NBR
SBR

Rubber mixture

Master data		
Item number	2029367	
Type	107 B PG36	
Description 1	Cutting ring	
Manufacturer	OBO	
Dimension	PG36	
Colour	Black	
Material	Rubber mixture	
Smallest sales unit	50	
Unit of quantity	Piece	
Weight	1.733 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,0685 kg COe / 1 Piece	


Technical data sheet

Cutting ring

Item number: 2029367



Dimensions

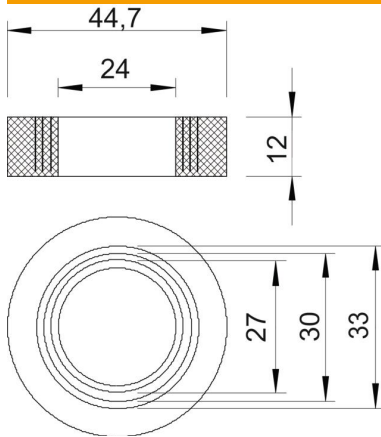

Dimension D1	24 mm
Dimension D2	44.7 mm
Dimension D3	27 mm
Dimension D4	30 mm
Dimension D5	33 mm
Dimension H	12 mm

Technical data

Sealing area D, max.	33 mm
Sealing area D, min.	24 mm
Size	Pg 36
Size	M40