


Technical data sheet

Pressure ring, PG thread

Item number: 2027119

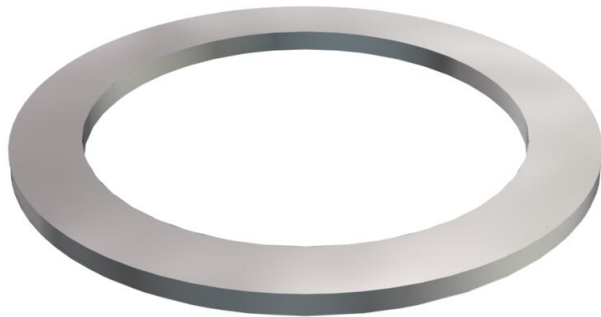

Pressure ring, Part 7, to DIN 46320, suitable for plastic and brass glands to DIN 46320.

Pg

St

Steel


GTP

Electrogalvanized, transparently passivated

Master data

Item number	2027119
Type	107 D PG11 GTP
Description 1	Pressure ring
Manufacturer	OBO
Dimension	PG11
Material	Steel
Surface	Electrogalvanized, transparently passivated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.052 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0039 kg COe / 1 Piece

Dimensions

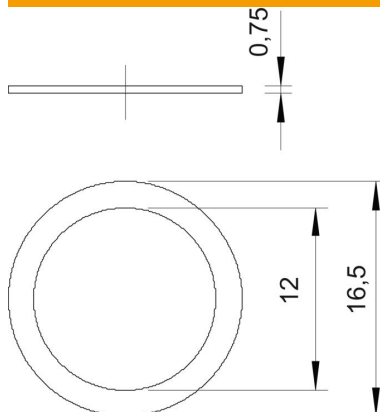

Dimension D1	16.5 mm
Dimension D2	12 mm

Technical data sheet

Pressure ring, PG thread

Item number: 2027119



Technical data

Version for	Miscellaneous
Screw for PG thread dimension	11
Inner diameter	12 mm