


# Technical data sheet

## Connection thread sealing ring, metric

Item number: 2030024

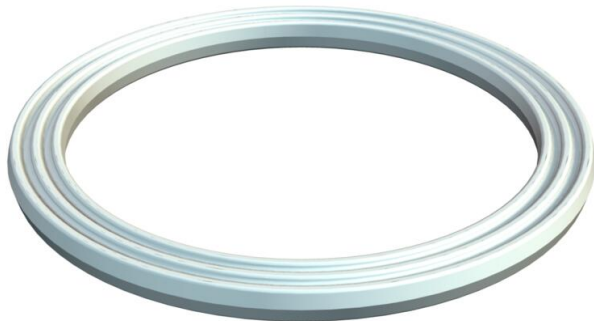

Connection thread sealing ring, suitable for all plastic cable glands, with metric thread according to DIN EN 60423 or ISO 68. The internal diameters of the sealing rings are designed in such a way that they can be pre-mounted in a captive manner.




PE

Polyethylene

### Master data

Item number	2030024
Type	107 F M40 PE
Description 1	Connection thread sealing ring
Manufacturer	OBO
Dimension	M40
Material	Polyethylene
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.2 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0052 kg COe / 1 Piece

### Dimensions

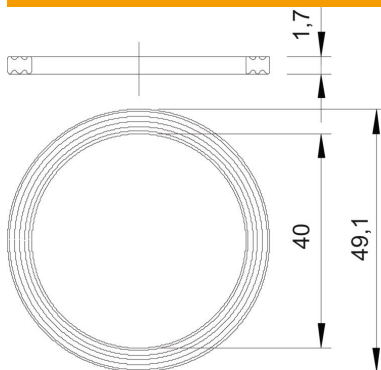

Dimension D1	49.1 mm
Dimension D2	40 mm
Dimension t	1.7 mm

# Technical data sheet

## Connection thread sealing ring, metric

Item number: 2030024



### Technical data

Version for	Flat sealing ring
Suitable for metric thread dimension	40
Inner diameter	40 mm