


Technical data sheet

Sealing plate, PG

Item number: 2029774

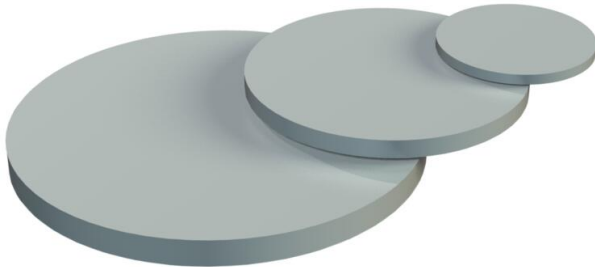

The sealing plate offers both mechanical protection and the maintenance of the protection rating of plastic and metal cable glands to DIN 46320 before cable installation.

Application: the discs are placed between the pressure screw and the pressure ring. If the safe maintenance of IP65 is required, we recommend placing the discs between the pressure ring and the sealing ring. To mount the cable, remove the discs – they can be reused.




PVC Polyvinylchloride

Master data

| | |
|---------------------|----------------------|
| Item number | 2029774 |
| Type | 107 V PG29 PVC |
| Description 1 | Sealing plate |
| Manufacturer | OBO |
| Dimension | PG29 |
| Colour | Light grey; RAL 7035 |
| Material | Polyvinylchloride |
| Smallest sales unit | 100 |
| Unit of quantity | Piece |
| Weight | 0.135 kg |
| Weight unit | kg/100 pc. |

Dimensions

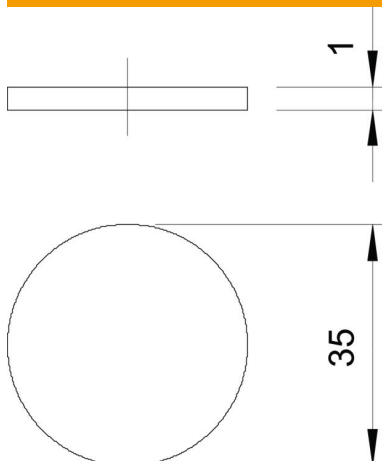

| | |
|-------------|-------|
| Dimension D | 35 mm |
| Dimension t | 1 mm |

Technical data sheet

Sealing plate, PG

Item number: 2029774



Technical data

| | |
|-------------------------------|---------------|
| Version for | Miscellaneous |
| Screw for PG thread dimension | 29 |