


Technical data sheet

Pressure screw, PG strain relief 107

Item number: 2023210

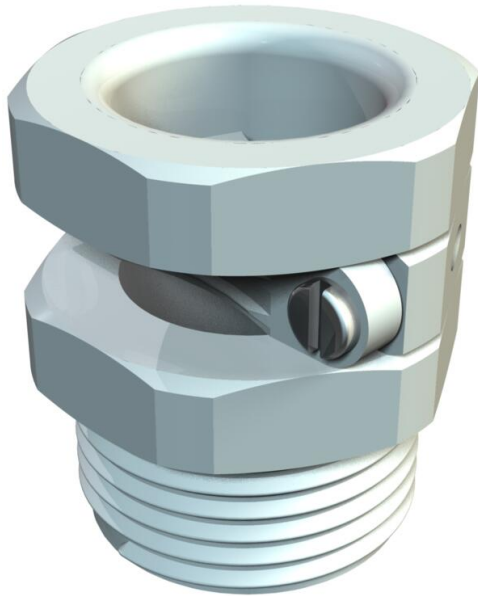

Pressure screw with transverse clip strain relief, electrogalvanised steel screws, PG thread to DIN 40430.



PA

Polyamide

Master data

Item number	2023210
Type	107 Z PG21 PA
Description 1	Pressure screw
Description 2	with strain relief
Manufacturer	OBO
Dimension	PG21
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	25
Unit of quantity	Piece
Weight	1.8 kg
Weight unit	kg/100 pc.


Technical data sheet

Pressure screw, PG strain relief 107

Item number: 2023210



Dimensions

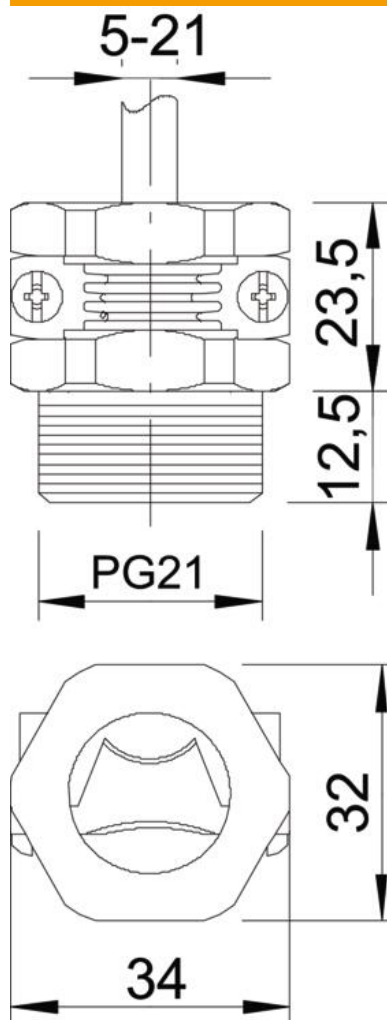

Dimension E	34 mm
Dimension L1	12.5 mm
Dimension L2	23.5 mm

Technical data

Thread type	PG
Nominal thread size	21
Thread increase	1.59 mm
Fibre-glass reinforced	no
Halogen-free	yes
Impact-resistant	no
WAF	32
Strain relief option	yes
Clamping range, max.	21.2 mm
Clamping range, min.	5.9 mm