

Technical data sheet

Screw plug, metric thread

Item number: 2033011



Screw plug in accordance with DIN 46320, with metric thread to IEC 423. Protection rating IP54, IP68 (5 bar/1h) possible in conjunction with sealing ring type 171.



PS Polystyrene

Master data

Item number	2033011
Type	108 M20 PS
Description 1	Screw plug
Manufacturer	OBO
Dimension	M20
Colour	Light grey; RAL 7035
Material	Polystyrene
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.128 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0067 kg COe / 1 Piece


Technical data sheet

Screw plug, metric thread

Item number: 2033011



Dimensions

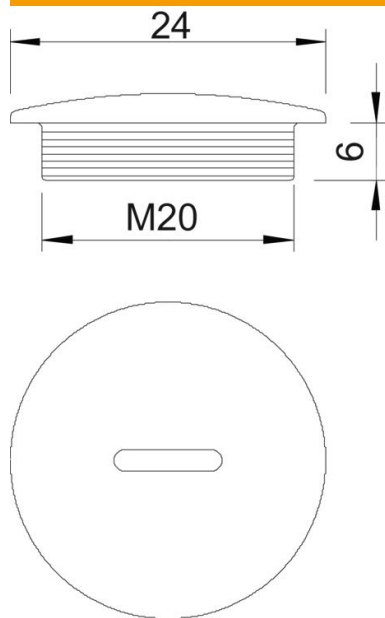

Dimension D	24 mm
Dimension L	6 mm

Technical data

explosion-proof	no
For Ex zone gas	Without
For Ex zone dust	Without
Thread	M20 x 1,5
Thread type	Metric
Nominal thread size metric/PG	20
Thread increase	1.5 mm
Fibre-glass reinforced	no
Halogen-free	yes
Unstable torque	2.5 Nm
Impact-resistant	yes
Protection rating	IP54