

# Technical data sheet

## Screw plug, metric thread

Item number: 2033032



Screw plug in accordance with DIN 46320, with metric thread to IEC 423. Protection rating IP54, IP68 (5 bar/1h) possible in conjunction with sealing ring type 171.



**PS** Polystyrene

### Master data

|                                    |                         |
|------------------------------------|-------------------------|
| Item number                        | 2033032                 |
| Type                               | 108 M50 PS              |
| Description 1                      | Screw plug              |
| Manufacturer                       | OBO                     |
| Dimension                          | M50                     |
| Colour                             | Light grey; RAL 7035    |
| Material                           | Polystyrene             |
| Smallest sales unit                | 25                      |
| Unit of quantity                   | Piece                   |
| Weight                             | 0.939 kg                |
| Weight unit                        | kg/100 pc.              |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0462 kg COe / 1 Piece |


# Technical data sheet

## Screw plug, metric thread

Item number: 2033032



### Dimensions

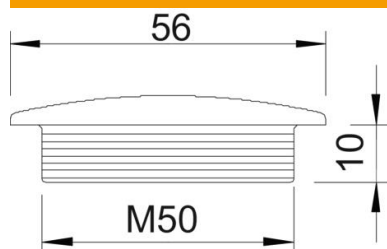

|             |       |
|-------------|-------|
| Dimension D | 56 mm |
| Dimension L | 10 mm |

### Technical data

|                               |           |
|-------------------------------|-----------|
| explosion-proof               | no        |
| For Ex zone gas               | Without   |
| For Ex zone dust              | Without   |
| Thread                        | M50 x 1,5 |
| Thread type                   | Metric    |
| Nominal thread size metric/PG | 50        |
| Thread increase               | 1.5 mm    |
| Fibre-glass reinforced        | no        |
| Halogen-free                  | yes       |
| Unstable torque               | 4.5 Nm    |
| Impact-resistant              | yes       |
| Protection rating             | IP54      |