

Technical data sheet

Screw plug, PG thread

Item number: 2033135



Screw plug in accordance with DIN 46320, with PG thread to DIN 40430. Protection rating IP54, IP68 (5 bar/1h) possible in conjunction with sealing ring type 171.



PS Polystyrene

Master data

Item number	2033135
Type	108 PG13.5
Description 1	Screw plug
Manufacturer	OBO
Dimension	PG13,5
Colour	Light grey; RAL 7035
Material	Polystyrene
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.164 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0067 kg COe / 1 Piece


Technical data sheet

Screw plug, PG thread

Item number: 2033135



Dimensions

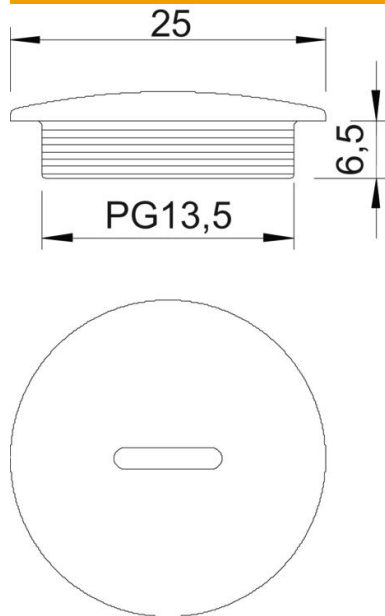

Dimension D	25 mm
Dimension L	6.5 mm

Technical data

explosion-proof	no
For Ex zone gas	Without
For Ex zone dust	Without
Thread	Pg 13,5
Thread type	PG
Nominal thread size metric/PG	13.5
Thread increase	1.41 mm
Fibre-glass reinforced	no
Halogen-free	yes
Unstable torque	2.5 Nm
Impact-resistant	yes
Protection rating	IP54