

Technical data sheet

Screw plug, PG thread

Item number: 2033364



Screw plug in accordance with DIN 46320, with PG thread to DIN 40430. Protection rating IP54, IP68 (5 bar/1h) possible in conjunction with sealing ring type 171.



PS Polystyrene

Master data

Item number	2033364
Type	108 PG36
Description 1	Screw plug
Manufacturer	OBO
Dimension	PG36
Colour	Light grey; RAL 7035
Material	Polystyrene
Smallest sales unit	25
Unit of quantity	Piece
Weight	1.057 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0441 kg COe / 1 Piece


Technical data sheet

Screw plug, PG thread

Item number: 2033364



Dimensions

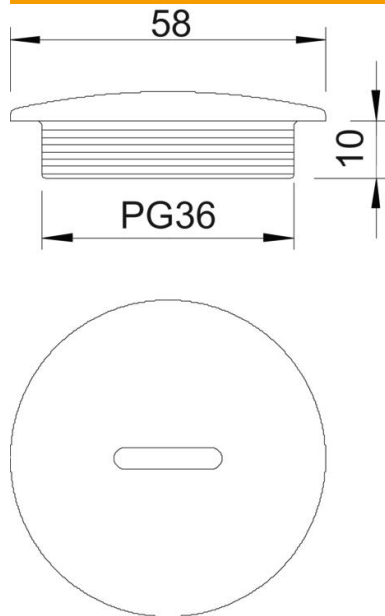

Dimension D	58 mm
Dimension L	10 mm

Technical data

explosion-proof	no
For Ex zone gas	Without
For Ex zone dust	Without
Thread	Pg 36
Thread type	PG
Nominal thread size metric/PG	36
Thread increase	1.59 mm
Fibre-glass reinforced	no
Halogen-free	yes
Unstable torque	4 Nm
Impact-resistant	yes
Protection rating	IP54