

Technical data sheet

Cable bracket Rd 8–10 mm with wood screw, plastic anchor

Item number: 5230322



- With female thread M8 or through hole Ø 7 mm
- Over-piece installed with 2 hexagonal bolts
- Version HD with wood screws (5 x 60) and plastic dowels (8 x 40)

Zn	Die-cast zinc
VZ	galvanised

Master data

Item number	5230322
Type	113 B-Z-HD
Description 1	Cable fixing device
Description 2	with wood screw
Manufacturer	OBO
Dimension	8-10mm
Material	Die-cast zinc
Surface	galvanised
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	6.58 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2787 kg CO2e / 1 Piece


Technical data sheet

Cable bracket Rd 8–10 mm with wood screw, plastic anchor

Item number: 5230322



Dimensions

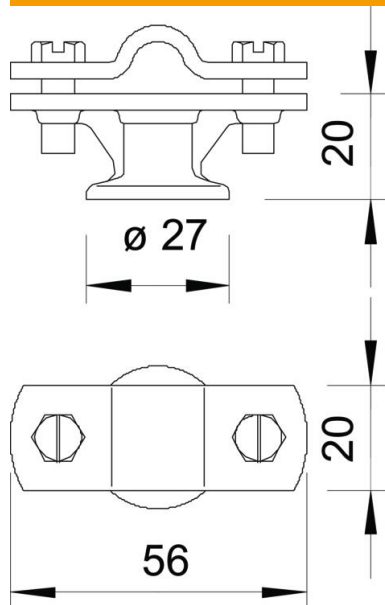

Technical data

Holder fastening type	Drill hole with M-thread
Conductor fastening type	With screw clip
Use in Ex area	yes
Thread metric	8
High voltage-resistant, insulated version	no
Cable dimensions	8–10 mm round
Material of the holder	Die-cast zinc
Material of the base	Die-cast zinc
Material of the crossbar	Die-cast zinc