

# Technical data sheet

## Locknut, metric thread

Item number: 2049562



Locknut to DIN 46319, with metric thread IEC 423.

Note: Only tighten polystyrene cable glands lightly due to the risk of stress crack formation.



PS Polystyrene

| Master data                       |                         |  |
|-----------------------------------|-------------------------|--|
| Item number                       | 2049562                 |  |
| Type                              | 116 M40 LGR PS          |  |
| Description 1                     | Locknut                 |  |
| Manufacturer                      | OBO                     |  |
| Dimension                         | M40                     |  |
| Colour                            | Light grey; RAL 7035    |  |
| Material                          | Polystyrene             |  |
| Smallest sales unit               | 25                      |  |
| Unit of quantity                  | Piece                   |  |
| Weight                            | 0.491 kg                |  |
| Weight unit                       | kg/100 pc.              |  |
| CO Footprint (GWP) Cradle-to-Gate | 0,0205 kg COe / 1 Piece |  |

# Technical data sheet

## Locknut, metric thread


Item number: 2049562



### Dimensions



|             |       |
|-------------|-------|
| Dimension E | 56 mm |
| Dimension L | 7 mm  |

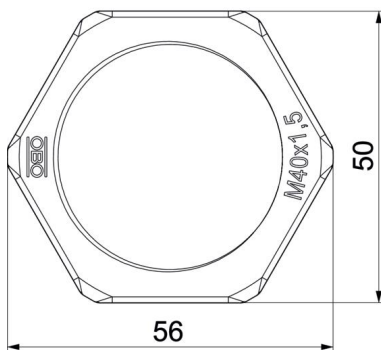

### Technical data

|                               |           |
|-------------------------------|-----------|
| Thread                        | M40_x_1,5 |
| Thread type                   | Metric    |
| Nominal thread size metric/PG | 40        |
| Fibre-glass reinforced        | no        |
| Halogen-free                  | yes       |
| Impact-resistant              | yes       |
| WAF                           | 50        |