

Technical data sheet

Locknut, metric thread, black

Item number: 2049112



Locknut DIN 46319, with metric thread IEC 423.



| Master data                        |                         |  |
|------------------------------------|-------------------------|--|
| Item number                        | 2049112                 |  |
| Type                               | 116 M40 SW PA           |  |
| Description 1                      | Locknut                 |  |
| Manufacturer                       | OBO                     |  |
| Dimension                          | M40                     |  |
| Colour                             | Black                   |  |
| Material                           | Polyamide               |  |
| Smallest sales unit                | 25                      |  |
| Unit of quantity                   | Piece                   |  |
| Weight                             | 0.602 kg                |  |
| Weight unit                        | kg/100 pc.              |  |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0293 kg COe / 1 Piece |  |

# Technical data sheet

Locknut, metric thread, black


Item number: 2049112



## Dimensions



|             |       |
|-------------|-------|
| Dimension E | 56 mm |
| Dimension L | 7 mm  |

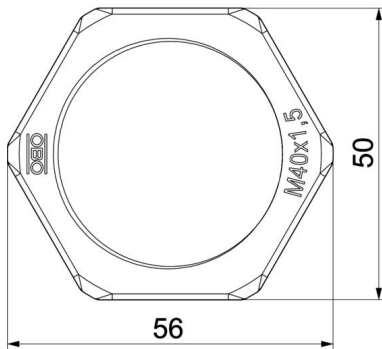

## Technical data

|                               |           |
|-------------------------------|-----------|
| Thread                        | M40_x_1,5 |
| Thread type                   | Metric    |
| Nominal thread size metric/PG | 40        |
| Fibre-glass reinforced        | no        |
| Halogen-free                  | yes       |
| Impact-resistant              | no        |
| WAF                           | 50        |