

# Technical data sheet

## Locknut, PG thread

Item number: 2043483



Locknut DIN 46320, with PG thread DIN 40430.

Note: Only tighten polystyrene cable glands lightly due to the risk of stress crack formation.



**PS** Polystyrene

| Master data                        |                       |  |
|------------------------------------|-----------------------|--|
| Item number                        | 2043483               |  |
| Type                               | 116 PG48              |  |
| Description 1                      | Locknut               |  |
| Manufacturer                       | OBO                   |  |
| Dimension                          | PG48                  |  |
| Colour                             | Light grey; RAL 7035  |  |
| Material                           | Polystyrene           |  |
| Smallest sales unit                | 25                    |  |
| Unit of quantity                   | Piece                 |  |
| Weight                             | 1.175 kg              |  |
| Weight unit                        | kg/100 pc.            |  |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,05 kg COe / 1 Piece |  |

# Technical data sheet

## Locknut, PG thread


Item number: 2043483



### Dimensions



|             |       |
|-------------|-------|
| Dimension E | 78 mm |
| Dimension L | 8 mm  |

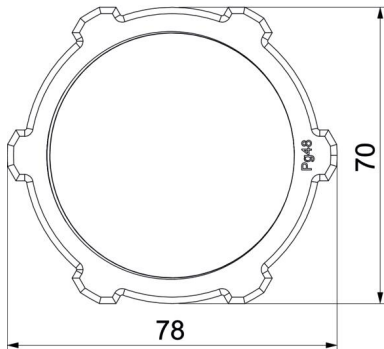

### Technical data

|                               |       |
|-------------------------------|-------|
| Thread                        | Pg_48 |
| Thread type                   | PG    |
| Nominal thread size metric/PG | 48    |
| Fibre-glass reinforced        | no    |
| Halogen-free                  | yes   |
| Impact-resistant              | yes   |
| WAF                           | 70    |