

Technical data sheet

Roof cable holder for ridge tiles with M8 threaded bolts

Item number: 5202568



- Adjustable from 180–240 mm
- With conductor 177/20, polyamide, grey
- With 3 M8 threaded nipples for positioning the holder

St

Steel

FT

Hot-dip galvanised

Master data

Item number	5202568
Type	132 GB-M8
Description 1	Roof conductor holder
Description 2	for ridge tiles with M8 bolt
Manufacturer	OBO
Dimension	M8
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	20
Unit of quantity	Piece
Weight	18.7 kg
Weight unit	kg/100 pc.


Technical data sheet

Roof cable holder for ridge tiles with M8 threaded bolts

Item number: 5202568



Dimensions

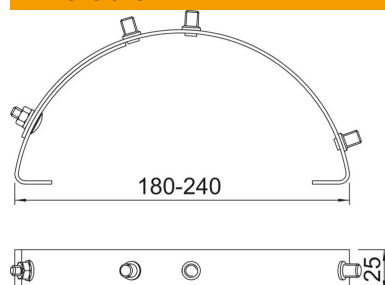

Technical data

Application	Ridge
Mounting type	Tensionable
Mounting height	20 mm
Material of the support	Steel, hot galvanised