

Technical data sheet

Expansion piece, metric thread

Item number: 2088282



Extension made from brass with metric inner and outer thread to mount metal or plastic cable glands on housings. IP54 protection rating without additional connection sleeve. Protection rating of up to IP68 possible with additional connection seal, such as an O-ring or flat sealing ring.



CuZn 37	Brass
N	Nickel-plated

Master data	
Item number	2088282
Type	165 ADA M20-25
Description 1	Extension
Description 2	M - M
Manufacturer	OBO
Dimension	M20-M25
Material	Brass
Surface	Nickel-plated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	2.09 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0535 kg COe / 1 Piece


Technical data sheet

Expansion piece, metric thread

Item number: 2088282



Dimensions

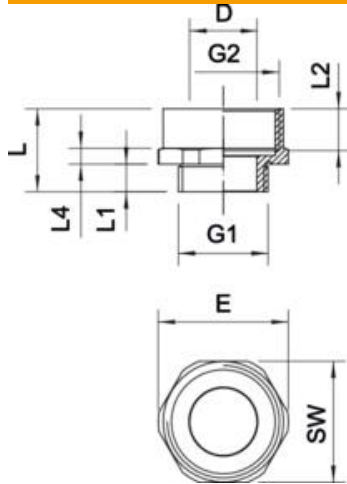

Dimension D	15 mm
Dimension E	29 mm
Dimension G1 (mm)	20
Dimension G2 (mm)	25
Dimension L	18.5 mm
Dimension L1	6.4 mm
Dimension L2	9 mm
Dimension L4	3.5 mm

Technical data

explosion-proof	no
Thread type: External thread	Metric
Thread type: Internal thread	Metric
Thread dimension, metric, external	20
Thread dimension, metric, internal	25
WAF	27
Nickel-plated	yes