

Technical data sheet

165 MBG... roof cable holder for flat roofs, black, with concrete

Item number: 5218704



- Closed form with base
- With double conductor holder
- Filling weight 1 kg (frost-resistant concrete)
- Sleeve made of polyethylene, black, UV-resistant and weather-resistant
- Base made of polyamide PA 6, black, UV-resistant and weather-resistant
- Base can be used on almost all roofing felt systems (bitumen, PVC)
- Types 165 MBG...FO: Packed in foil bag

PA/
PE

Polyamide/Polyethylene

Master data

| | |
|------------------------------------|--------------------------|
| Item number | 5218704 |
| Type | 165 MBG-8-10 FO |
| Description 1 | Roof conductor holder |
| Description 2 | for flat roofs |
| Manufacturer | OBO |
| Dimension | 8-10mm |
| Colour | Black |
| Material | Polyamide/Polyethylene |
| Smallest sales unit | 12 |
| Unit of quantity | Piece |
| Weight | 100 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,5082 kg CO2e / 1 Piece |


Technical data sheet

165 MBG... roof cable holder for flat roofs, black, with concrete


Item number: 5218704



Dimensions

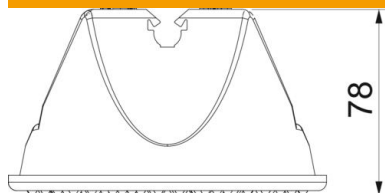

| | |
|--------|----------|
| Length | 133.5 mm |
|--------|----------|

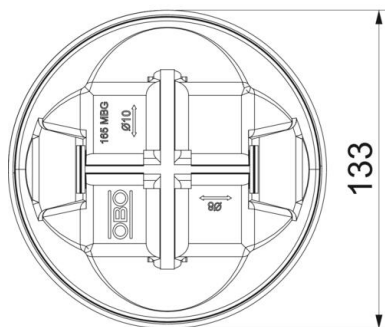

Technical data

| | |
|--------------------------|---------------|
| Application | Flat roof |
| Conductor fastening type | With clip |
| Conductor diameter, max. | 10 |
| Conductor diameter, min. | 8 |
| Mounting type | Miscellaneous |
| Fit | Rd 8-10 mm |
| Clamping range D, max. | 10 mm |
| Clamping range D, min. | 8 mm |
| Material of the holder | Plastic |
| Material of the support | Concrete |