


# Technical data sheet

## Screw plug, PG thread

Item number: 2090422

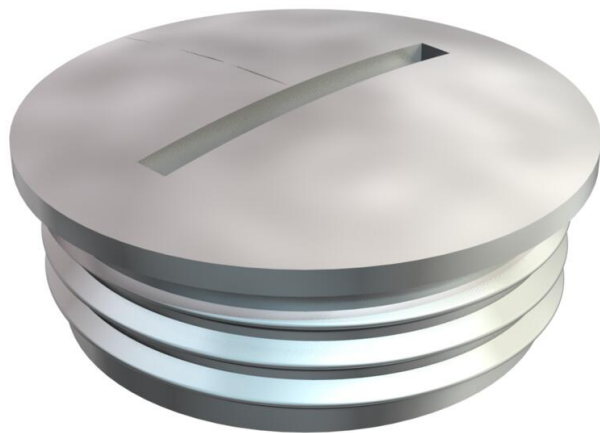

Screw plug N in accordance with DIN 46320, with PG thread to DIN 40430.

In conjunction with sealing ring, types 107, 170 or 171, protection rating IP68 (5 bar/1 hr).

Sealing ring not contained in the scope of delivery.

\* Prices according to DEL notation.



Brass



Nickel-plated

### Master data

Item number	2090422
Type	168 MS PG42
Description 1	Screw plug
Manufacturer	OBO
Dimension	PG42
Material	Brass
Surface	Nickel-plated
Surface standard	
Smallest sales unit	25
Unit of quantity	Piece
Weight	11.71 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,3154 kg COe / 1 Piece


# Technical data sheet

## Screw plug, PG thread

Item number: 2090422



### Dimensions

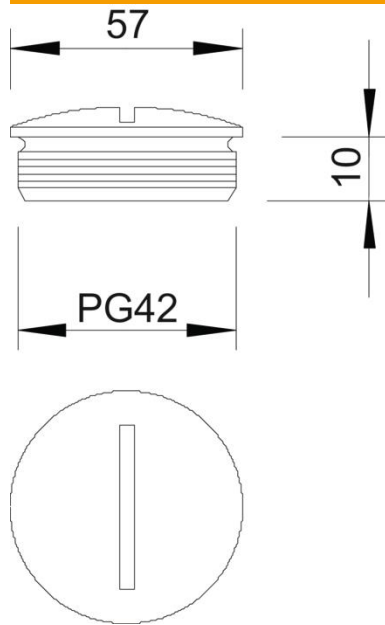

Dimension D	57 mm
Dimension L	10 mm

### Technical data

explosion-proof	no
For Ex zone gas	Without
For Ex zone dust	Without
Thread	Pg 42
Thread type	PG
Nominal thread size metric/PG	42
Thread increase	1.59 mm
Fibre-glass reinforced	no
Halogen-free	yes
Impact-resistant	no
Protection rating	IP68