

# Technical data sheet

## Locknut, metric thread with cutting teeth

Item number: 2091709



Locknuts DIN 46319 with metric thread IEC 423.

\* Prices according to DEL notation.



**CuZn**  
37 Brass

**N** Nickel-plated

### Master data

|                                   |                         |
|-----------------------------------|-------------------------|
| Item number                       | 2091709                 |
| Type                              | 169 MSS M16             |
| Description 1                     | Locknut                 |
| Description 2                     | with cutting teeth      |
| Manufacturer                      | OBO                     |
| Dimension                         | M16x1,5                 |
| Material                          | Brass                   |
| Surface                           | Nickel-plated           |
| Surface standard                  |                         |
| Smallest sales unit               | 50                      |
| Unit of quantity                  | Piece                   |
| Weight                            | 0.49 kg                 |
| Weight unit                       | kg/100 pc.              |
| CO Footprint (GWP) Cradle-to-Gate | 0,0116 kg COe / 1 Piece |


# Technical data sheet

## Locknut, metric thread with cutting teeth

Item number: 2091709



### Dimensions

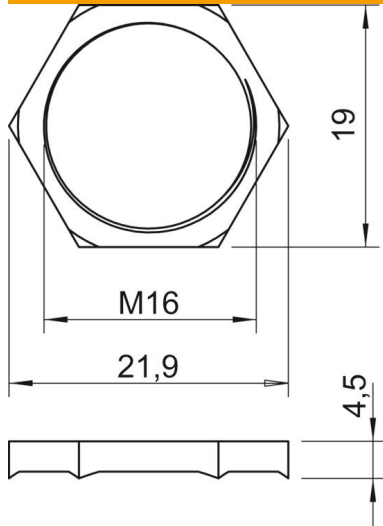

|             |         |
|-------------|---------|
| Dimension E | 21.9 mm |
| Dimension L | 4.5 mm  |

### Technical data

|                               |           |
|-------------------------------|-----------|
| Thread                        | M16_x_1,5 |
| Thread type                   | Metric    |
| Nominal thread size metric/PG | 16        |
| Fibre-glass reinforced        | no        |
| Halogen-free                  | no        |
| Impact-resistant              | no        |
| WAF                           | 19        |