

# Technical data sheet

## Locknut, metric thread

Item number: 2091615



Locknut to DIN 46319 with metric thread IEC 423.

\* Prices according to DEL notation.



Brass



Nickel-plated

### Master data

|                                   |                        |
|-----------------------------------|------------------------|
| Item number                       | 2091615                |
| Type                              | 169 MS M16             |
| Description 1                     | Locknut                |
| Manufacturer                      | OBO                    |
| Dimension                         | M16                    |
| Material                          | Brass                  |
| Surface                           | Nickel-plated          |
| Surface standard                  |                        |
| Smallest sales unit               | 100                    |
| Unit of quantity                  | Piece                  |
| Weight                            | 0.31 kg                |
| Weight unit                       | kg/100 pc.             |
| CO Footprint (GWP) Cradle-to-Gate | 0,008 kg COe / 1 Piece |


# Technical data sheet

## Locknut, metric thread

Item number: 2091615



### Dimensions

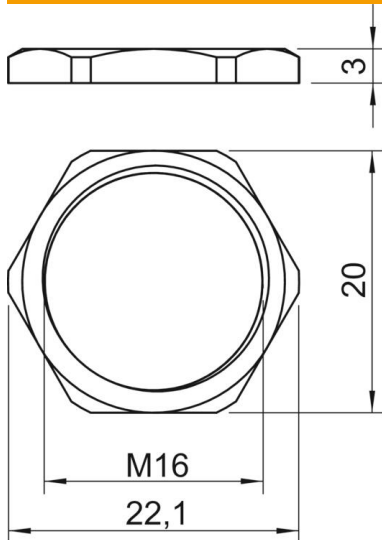

|             |         |
|-------------|---------|
| Dimension E | 22.1 mm |
| Dimension L | 3 mm    |

### Technical data

|                               |           |
|-------------------------------|-----------|
| Thread                        | M16_x_1,5 |
| Thread type                   | Metric    |
| Nominal thread size metric/PG | 16        |
| Fibre-glass reinforced        | no        |
| Halogen-free                  | no        |
| Impact-resistant              | no        |
| WAF                           | 20        |