

# Technical data sheet

## Cable bracket Rd 8–10 mm, with wood screw thread

Item number: 5227100



- Also for flat conductor to FL 30
- With wood screw thread
- Bottom section, hot-dip galvanised cast iron
- Over-piece and screws, hot dipped galvanised steel

SG	cast steel
F	Hot galvanized

### Master data

Item number	5227100
Type	176 A 100
Description 1	Cable fixing device
Manufacturer	OBO
Dimension	100mm
Material	cast steel
Surface	Hot galvanized
Surface standard	DIN 267, Teil 10
Smallest sales unit	50
Unit of quantity	Piece
Weight	11.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2194 kg CO2e / 1 Piece


# Technical data sheet

Cable bracket Rd 8–10 mm, with wood screw thread

Item number: 5227100



## Dimensions

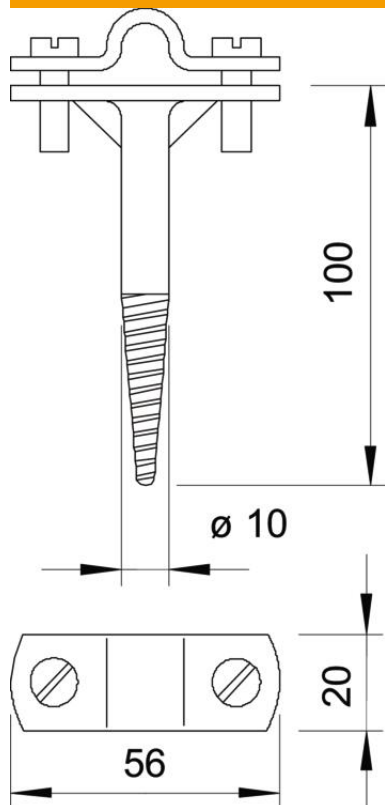

Length	100 mm
Dimension H	100 mm

## Technical data

Holder fastening type	With wood screw thread tip
Conductor fastening type	With screw clip
Use in Ex area	yes
High voltage-resistant, insulated version	no
Cable dimensions	8–10 mm round
Material of the holder	Malleable iron
Material of the base	Malleable iron
Material of the crossbar	Malleable iron