

Technical data sheet

Cable bracket Rd 8–10 mm, with wood screw thread

Item number: 5227151



- Also for flat conductor to FL 30
- With wood screw thread
- Bottom section, hot-dip galvanised cast iron
- Over-piece and screws, hot dipped galvanised steel

SG	cast steel
F	Hot galvanized

Master data

Item number	5227151
Type	176 A 150
Description 1	Cable fixing device
Manufacturer	OBO
Dimension	150mm
Material	cast steel
Surface	Hot galvanized
Surface standard	DIN 267, Teil 10
Smallest sales unit	20
Unit of quantity	Piece
Weight	13.1 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2653 kg CO2e / 1 Piece


Technical data sheet

Cable bracket Rd 8–10 mm, with wood screw thread

Item number: 5227151



Dimensions

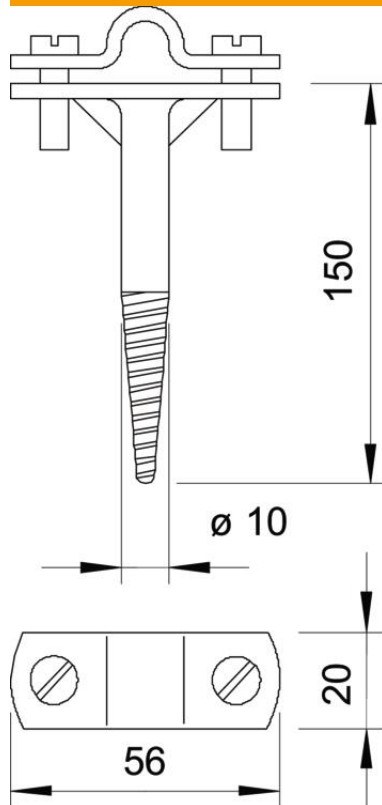

Length	150 mm
Dimension H	150 mm

Technical data

Holder fastening type	With wood screw thread tip
Conductor fastening type	With screw clip
Use in Ex area	yes
High voltage-resistant, insulated version	no
Cable dimensions	8–10 mm round
Material of the holder	Malleable iron
Material of the base	Malleable iron
Material of the crossbar	Malleable iron