

Technical data sheet

BKS clamp clip

Item number: 2148862



For cables, flexible pipes and all kinds of insulating and armoured steel pipes, suitable for concrete, calcareous limestone and full brick. Use in gas concrete masonry is possible, but reduced load capacities must be expected.



PA Polyamide

Master data

Item number	2148862
Type	1973 20-40 LGR
Description 1	BKS clamp
Manufacturer	OBO
Dimension	20-40mm
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.15 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0092 kg COe / 1 Piece


Technical data sheet

BKS clamp clip

Item number: 2148862



Dimensions

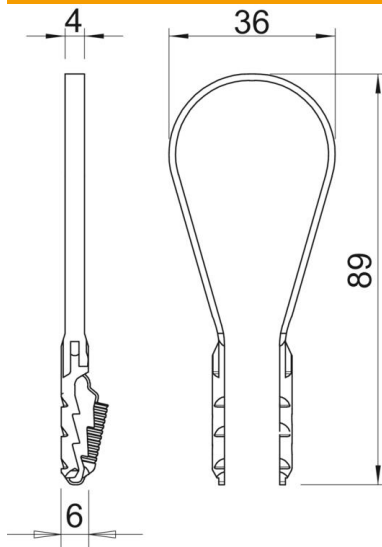

Dimension D	36 mm
Dimension L	89 mm

Technical data

Version for	Closed
Pull-out value	500 N
Fastening type	Plug fastening
Drill hole depth	70 mm
Drill hole diameter, min.	6 mm
Halogen-free	yes
Clamping range D, max.	40 mm
Clamping range D, min.	20 mm