

Technical data sheet

BKS clamp clip

Item number: 2148846



For cables, flexible pipes and all kinds of insulating and armoured steel pipes, suitable for concrete, calcareous limestone and full brick. Use in gas concrete masonry is possible, but reduced load capacities must be expected.



PA Polyamide

Master data

Item number	2148846
Type	1973 8-28 LGR
Description 1	BKS clamp
Manufacturer	OBO
Dimension	8-28mm
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.122 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0075 kg COe / 1 Piece


Technical data sheet

BKS clamp clip

Item number: 2148846



Dimensions

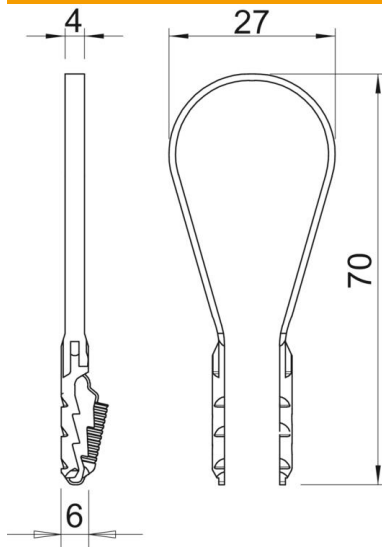

Dimension D	27 mm
Dimension L	70 mm

Technical data

Version for	Closed
Pull-out value	500 N
Fastening type	Plug fastening
Drill hole depth	65 mm
Drill hole diameter, min.	6 mm
Halogen-free	yes
Clamping range D, max.	28 mm
Clamping range D, min.	8 mm