

# Technical data sheet

ISO nail clip 2007, black

Item number: 2232146



ISO nail clip, short design



PP

Polypropylene

## Master data

|                                    |                         |
|------------------------------------|-------------------------|
| Item number                        | 2232146                 |
| Type                               | 2007 25 SW              |
| Description 1                      | ISO nail clip           |
| Manufacturer                       | OBO                     |
| Dimension                          | 7mm, L25                |
| Colour                             | Jet black; RAL 9005     |
| Material                           | Polypropylene           |
| Smallest sales unit                | 100                     |
| Unit of quantity                   | Piece                   |
| Weight                             | 0.097 kg                |
| Weight unit                        | kg/100 pc.              |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0034 kg COe / 1 Piece |


# Technical data sheet

## ISO nail clip 2007, black

Item number: 2232146



### Dimensions

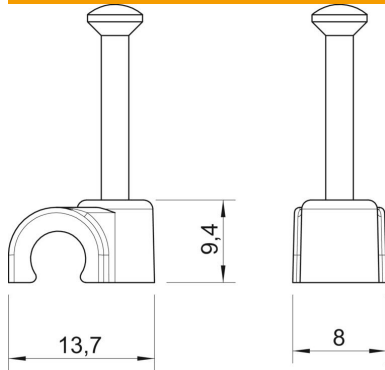

|             |         |
|-------------|---------|
| Dimension B | 8 mm    |
| Dimension H | 9.4 mm  |
| Dimension L | 13.7 mm |

### Technical data

|                    |                             |
|--------------------|-----------------------------|
| Double clip        | no                          |
| Shape              | Round (for round conductor) |
| for cable diameter | 7 mm                        |
| For nail diameter  | 2,0x25                      |
| Hardened           | yes                         |
| Halogen-free       | yes                         |
| With nail          | yes                         |
| Nail length        | 25 mm                       |
| Impact-resistant   | no                          |
| Transparent        | no                          |
| Pipe locking       | no                          |