

# Technical data sheet

## ISO nail clip 2018, light grey

Item number: 2228319



ISO nail clip, short design



PP

Polypropylene

### Master data

|                                    |                         |
|------------------------------------|-------------------------|
| Item number                        | 2228319                 |
| Type                               | 2018 50 LGR             |
| Description 1                      | ISO nail clip           |
| Manufacturer                       | OBO                     |
| Dimension                          | 18mm, L50               |
| Colour                             | Light grey; RAL 7035    |
| Material                           | Polypropylene           |
| Smallest sales unit                | 25                      |
| Unit of quantity                   | Piece                   |
| Weight                             | 0.7 kg                  |
| Weight unit                        | kg/100 pc.              |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0162 kg COe / 1 Piece |


# Technical data sheet

ISO nail clip 2018, light grey

Item number: 2228319



## Dimensions

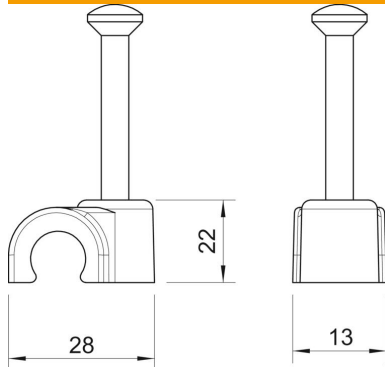

|             |       |
|-------------|-------|
| Dimension B | 13 mm |
| Dimension H | 22 mm |
| Dimension L | 28 mm |

## Technical data

|                    |                             |
|--------------------|-----------------------------|
| Double clip        | no                          |
| Shape              | Round (for round conductor) |
| for cable diameter | 18 mm                       |
| For nail diameter  | 2.5x50                      |
| Hardened           | yes                         |
| Halogen-free       | yes                         |
| With nail          | yes                         |
| Nail length        | 50 mm                       |
| Impact-resistant   | no                          |
| Transparent        | no                          |
| Pipe locking       | no                          |