

Technical data sheet

Adhesive clip 2025, light grey

Item number: 2228637



Adhesive clip, for clamping to the cable.



| Master data         |                      |  |
|---------------------|----------------------|--|
| Item number         | 2228637              |  |
| Type                | 2025 30 LGR          |  |
| Description 1       | Self-retaining clip  |  |
| Manufacturer        | OBO                  |  |
| Dimension           | 4-7mm, L30           |  |
| Colour              | Light grey; RAL 7035 |  |
| Material            | Polypropylene        |  |
| Smallest sales unit | 100                  |  |
| Unit of quantity    | Piece                |  |
| Weight              | 0.097 kg             |  |
| Weight unit         | kg/100 pc.           |  |


# Technical data sheet

Adhesive clip 2025, light grey

Item number: 2228637



## Dimensions

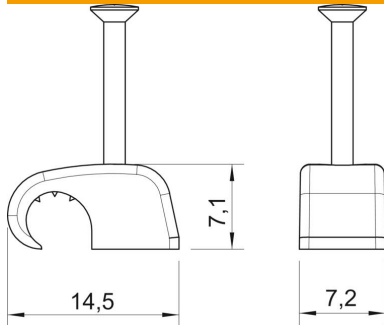

|             |         |
|-------------|---------|
| Dimension B | 7.2 mm  |
| Dimension H | 7.1 mm  |
| Dimension L | 14.5 mm |

## Technical data

|                          |                             |
|--------------------------|-----------------------------|
| Double clip              | no                          |
| Shape                    | Round (for round conductor) |
| for cable diameter, max. | 7 mm                        |
| for cable diameter, min. | 4 mm                        |
| For nail diameter        | 2 x 30                      |
| Hardened                 | yes                         |
| Halogen-free             | yes                         |
| With nail                | yes                         |
| Nail length              | 30 mm                       |
| Impact-resistant         | yes                         |
| Pipe locking             | no                          |