

Technical data sheet

Adhesive clip 2028, light grey

Item number: 2228904



Adhesive clip, for clamping to the cable.



| Master data                        |                         |  |
|------------------------------------|-------------------------|--|
| Item number                        | 2228904                 |  |
| Type                               | 2028 40 LGR             |  |
| Description 1                      | Self-retaining clip     |  |
| Manufacturer                       | OBO                     |  |
| Dimension                          | 14-17mm, L40            |  |
| Colour                             | Light grey; RAL 7035    |  |
| Material                           | Polypropylene           |  |
| Smallest sales unit                | 100                     |  |
| Unit of quantity                   | Piece                   |  |
| Weight                             | 0.27 kg                 |  |
| Weight unit                        | kg/100 pc.              |  |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0111 kg COe / 1 Piece |  |


# Technical data sheet

Adhesive clip 2028, light grey

Item number: 2228904



## Dimensions

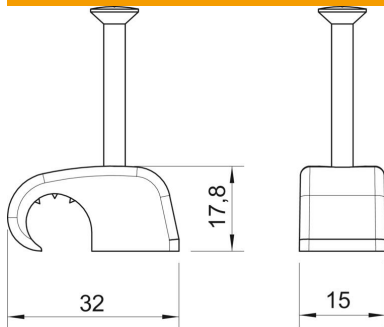

|             |         |
|-------------|---------|
| Dimension B | 15 mm   |
| Dimension H | 17.8 mm |
| Dimension L | 32 mm   |

## Technical data

|                          |                             |
|--------------------------|-----------------------------|
| Double clip              | no                          |
| Shape                    | Round (for round conductor) |
| for cable diameter, max. | 17 mm                       |
| for cable diameter, min. | 14 mm                       |
| For nail diameter        | 2,0 x 40                    |
| Hardened                 | yes                         |
| Halogen-free             | yes                         |
| With nail                | yes                         |
| Nail length              | 40 mm                       |
| Impact-resistant         | yes                         |
| Pipe locking             | no                          |