

# Technical data sheet

## Grip 10

Item number: 2205380



Cable tidy for general use with fastening holes of Ø 6 mm, suitable for wall and ceiling mounting. The moulded fastening element can be fastened using knock-in anchors or a gas pressure nail gun. The recommended fastening spacing when assigned fully is 50 to 60 cm.

Capacity:  
2031/ 10 max. 10 cables NYM 3 x 1.5 mm<sup>2</sup>



**PP** Polypropylene

### Master data

|                     |                          |
|---------------------|--------------------------|
| Item number         | 2205380                  |
| Type                | 2031 10                  |
| Description 1       | Grip collecting clamp    |
| Description 2       | with arrangement contour |
| Manufacturer        | OBO                      |
| Dimension           | 10x NYM3x1,5             |
| Colour              | Light grey; RAL 7035     |
| Material            | Polypropylene            |
| Smallest sales unit | 50                       |
| Unit of quantity    | Piece                    |
| Weight              | 1.41 kg                  |
| Weight unit         | kg/100 pc.               |


# Technical data sheet

## Grip 10

Item number: 2205380



### Dimensions

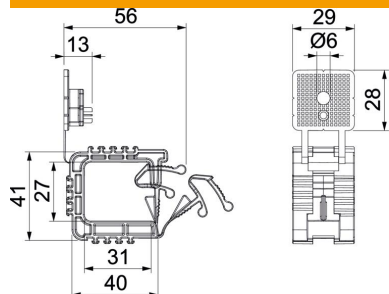

### Technical data

|                               |         |
|-------------------------------|---------|
| No. of conductors NYM 3 x 1.5 | 10      |
| Flame-resistant version       | no      |
| Breaking load                 | 0.32 kN |
| Maintain electrical functions | no      |
| Halogen-free                  | yes     |
| With anchor                   | no      |