

# Technical data sheet

## Pressure clip with knock-in anchor, for 8 cables

Item number: 2204851



With pre-mounted knock-in anchor, 6 mm Ø.  
Required drill hole depth 50 mm.  
Clamping height 9 mm – with spacer 13 mm.  
Fastening hole 6 mm Ø.  
2032/SD for max. 8 cables NYM 3 x 1.5 mm²



PA Polyamide

### Master data

|                                    |                         |
|------------------------------------|-------------------------|
| Item number                        | 2204851                 |
| Type                               | 2032 SD SP              |
| Description 1                      | Pressure clip           |
| Description 2                      | large packaging         |
| Manufacturer                       | OBO                     |
| Dimension                          | 1x8 NYM3x1,5            |
| Colour                             | Light grey; RAL 7035    |
| Material                           | Polyamide               |
| Smallest sales unit                | 100                     |
| Unit of quantity                   | Piece                   |
| Weight                             | 1.791 kg                |
| Weight unit                        | kg/100 pc.              |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0805 kg COe / 1 Piece |


# Technical data sheet

Pressure clip with knock-in anchor, for 8 cables

Item number: 2204851



## Dimensions

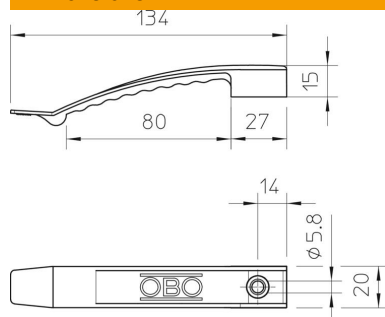

## Technical data

|                               |     |
|-------------------------------|-----|
| No. of conductors NYM 3 x 1.5 | 8   |
| Flame-resistant version       | no  |
| Maintain electrical functions | no  |
| Halogen-free                  | yes |
| With anchor                   | yes |