


Technical data sheet

Pressure clip for 8 cables

Item number: 2204975

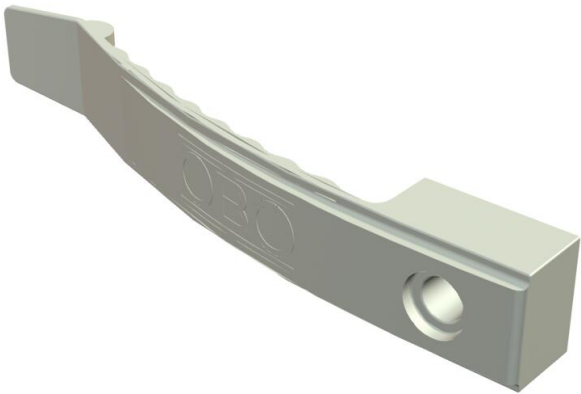

Standard version for general use, e.g. on intermediate ceilings and partition walls.
Clamping height 9 mm – with spacer 13 mm.
Fastening hole: 6 mm Ø.
2032 for max. 8 cables NYM 3 x 1.5 mm²



PA

Polyamide

Master data	
Item number	2204975
Type	2032 SP
Description 1	Pressure clip
Description 2	large packaging
Manufacturer	OBO
Dimension	1x8 NYM3x1,5
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.371 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0562 kg COe / 1 Piece


Technical data sheet

Pressure clip for 8 cables

Item number: 2204975



Dimensions

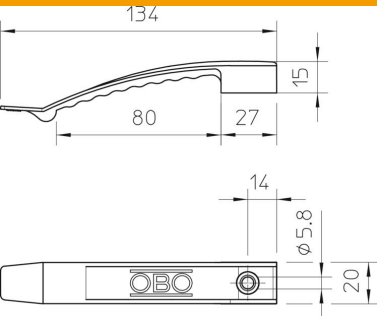

Technical data

No. of conductors NYM 3 x 1.5	8
Flame-resistant version	no
Maintain electrical functions	no
Halogen-free	yes
With anchor	no