

Technical data sheet

Pressure clip for 16 cables

Item number: 2204000



The metal pressure clip is halogen and fire load-free, and maintains a good mechanical stability even in fires. The pressure clip is also approved as a cable-specific variant for the maintenance of electrical functionality to DIN 4102 Part 12. The spacer 2033 D 15 x 3 G (must be ordered separately) increases the clamping height of pressure clips from 10 to 13 mm. The pressure clips are suitable for fireproof mounting above suspended fire protection ceilings in accordance with DIN 4102.




A2 Stainless steel

2B Bright, treated

Master data

Item number	2204000
Type	2033 M A2
Description 1	Pressure clip
Manufacturer	OBO
Dimension	2x8 NYM3x1,5
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	25
Unit of quantity	Piece
Weight	2.31 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,1762 kg COe / 1 Piece

Dimensions

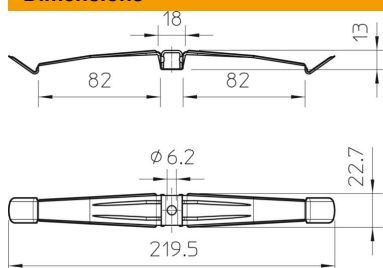

Technical data

No. of conductors NYM 3 x 1.5	16
Flame-resistant version	no
Maintain electrical functions	yes
Halogen-free	yes
With anchor	no