

Technical data sheet

Pressure clip for 10 cables

Item number: 2204991



Standard version for general use, e.g. on intermediate ceilings and partition walls.

Clamping height 9 mm – with spacer 13 mm.

Fastening hole: 6 mm Ø.

2034 for max. 10 cables NYM 3 x 1.5 mm²




PA

Polyamide

Master data

Item number	2204991
Type	2034 SP
Description 1	Pressure clip
Description 2	large packaging
Manufacturer	OBO
Dimension	2x5 NYM3x1,5
Colour	Light grey; RAL 7035
Material	Polyamide
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.169 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0492 kg COe / 1 Piece

Dimensions

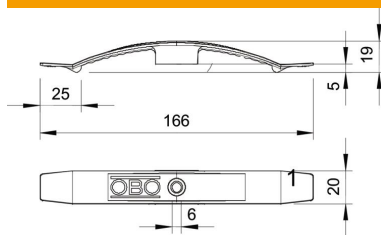

Technical data

No. of conductors NYM 3 x 1.5	10
Flame-resistant version	no
Maintain electrical functions	no
Halogen-free	yes
With anchor	no