

Technical data sheet

Series clip, light grey

Item number: 2254026



Also suitable for rails of 11 ÷ 12 mm slot width; polystyrene clip element, impact resistant, halogen-free, light grey RAL 7035; metal parts: electrogalvanised steel.



PS Polystyrene

Master data	
Item number	2254026
Type	2050 5-25 LGR
Description 1	Series clip
Description 2	with cross-head screw
Manufacturer	OBO
Dimension	5-25mm
Colour	Light grey; RAL 7035
Material	Polystyrene
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.631 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0219 kg COe / 1 Piece


Technical data sheet

Series clip, light grey

Item number: 2254026



Dimensions

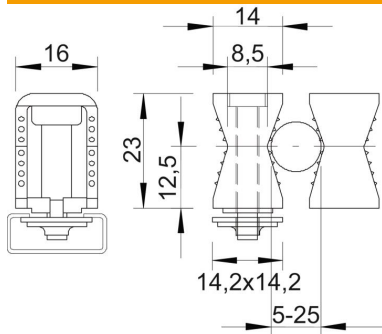

Dimension B	14 mm
Dimension B1	7.5 mm
Dimension H	24 mm
Dimension H1	12.5 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Fastening type	Rail fastening
for rail with slot width (with interval), max.	12 mm
for rail with slot width (with interval), min.	11 mm
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Nominal diameter	25 mm
Impact-resistant	no
Bolt	M4 x 30
Clamping range D, max.	25 mm
Clamping range D, min.	5 mm
UV-resistant	no