

Technical data sheet

Series clip, black

Item number: 2254565



Also suitable for rails of 11 ÷ 12 mm slot width; polystyrene clip element, impact resistant, halogen-free, light grey RAL 7035; metal parts: electrogalvanised steel.



PS Polystyrene

Master data	
Item number	2254565
Type	2051 8-36 SW
Description 1	Series clip
Description 2	with cross-head screw
Manufacturer	OBO
Dimension	8-36mm
Colour	Graphite black; RAL 9011
Material	Polystyrene
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.97 kg
Weight unit	kg/100 pc.

Technical data sheet


Series clip, black

Item number: 2254565



Dimensions

M4x37,5

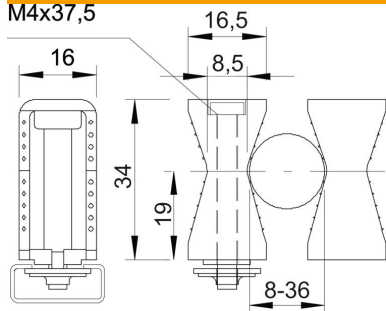

Dimension B	17 mm
Dimension B1	7.5 mm
Dimension H	34 mm
Dimension H1	18 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Fastening type	Rail fastening
for rail with slot width (with interval), max.	12 mm
for rail with slot width (with interval), min.	11 mm
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Nominal diameter	36 mm
Impact-resistant	no
Bolt	M4 x 40
Clamping range D, max.	36 mm
Clamping range D, min.	8 mm
UV-resistant	no