

Technical data sheet

Series clip, light grey

Item number: 2255022



Heavyweight version, also suitable for rails of 16 ÷ 17 mm slot width; polyamide clip element, light grey RAL 7035; Metal parts: Electrogalvanised steel.



PA Polyamide

Master data		
Item number	2255022	
Type	2055 24-72 LGR	
Description 1	Series clip	
Description 2	with cross-head screw	
Manufacturer	OBO	
Dimension	24-72mm	
Colour	Light grey; RAL 7035	
Material	Polyamide	
Smallest sales unit	20	
Unit of quantity	Piece	
Weight	6.471 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,2224 kg COe / 1 Piece	


Technical data sheet

Series clip, light grey

Item number: 2255022



Dimensions

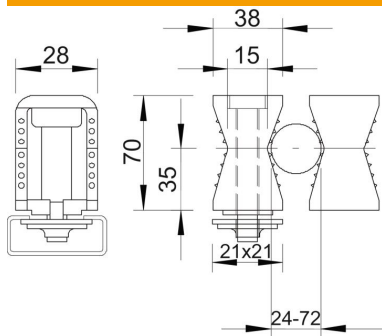

Dimension B	38 mm
Dimension B1	14.5 mm
Dimension H	70 mm
Dimension H1	37 mm

Technical data

Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Rail fastening
for rail with slot width (with interval), max.	17 mm
for rail with slot width (with interval), min.	16 mm
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Impact-resistant	no
Bolt	M8 x 80
Clamping range D, max.	72 mm
Clamping range D, min.	24 mm
UV-resistant	no